

Module 3.0



Spur gear

Pre-treated or case hardened steel

Quality grade 7e25



- **Quality grade 7e25 DIN 3961 (AGMA Q10)**

- Material :

Pre-treated steel 35NCD6, 28HRC

Case hardened steel 20NCD2 58HRC

- Teeth conform to DIN 867

- Tooth thickness conforms to DIN 3967

- Efficiency approx 98%

Options

- Alternative bores (H7)

- Keyway conforming to DIN6885 (JS9)


- Tapped hole

- Hole for dowel pin

Info.

- Torque figures are for 100 rpm and are given as a guide only

- Grade and tolerances measured before heat treatment.

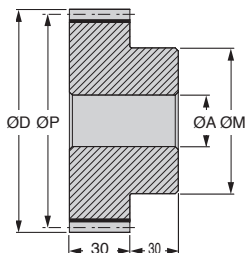

DISCOUNTS

Qty	1+	6+	19+	50+
Disc.	List	-5%	-10%	On request

Part number	Z	OP	OD	OA	OM	Backlash	Torque (Nm)	Weight	Price each 1 to 5			
Standard	hardened	Teeth	Pitch	External Bore	Bore	(mm)	Standard	hardened	Standard hardened			
PSG3.0-18	PSG3.0-18H	18	54	60	14	45	0.171 - 0.069	38,23	140,16	0,835	73,64 €	121,52 €
PSG3.0-19	PSG3.0-19H	19	57	63	14	45	0.171 - 0.069	40,35	147,95	0,896	76,40 €	126,12 €
PSG3.0-20	PSG3.0-20H	20	60	66	14	45	0.171 - 0.069	53,71	196,92	0,960	78,94 €	130,22 €
PSG3.0-21	PSG3.0-21H	21	63	69	16	55	0.171 - 0.069	56,39	206,77	1,190	81,51 €	134,49 €
PSG3.0-22	PSG3.0-22H	22	66	72	16	55	0.171 - 0.069	59,08	216,61	1,261	84,29 €	139,14 €
PSG3.0-23	PSG3.0-23H	23	69	75	16	55	0.171 - 0.069	61,76	226,46	1,335	86,98 €	143,58 €
PSG3.0-24	PSG3.0-24H	24	72	78	16	55	0.171 - 0.069	64,45	236,31	1,412	89,48 €	147,65 €
PSG3.0-25	PSG3.0-25H	25	75	81	16	55	0.171 - 0.069	67,13	246,15	1,493	94,91 €	156,61 €
PSG3.0-26	PSG3.0-26H	26	78	84	16	55	0.171 - 0.069	82,14	301,17	1,577	100,34 €	165,62 €
PSG3.0-27	PSG3.0-27H	27	81	87	16	55	0.173 - 0.067	85,30	312,76	1,664	102,77 €	169,59 €
PSG3.0-28	PSG3.0-28H	28	84	90	16	55	0.173 - 0.067	88,46	324,34	1,755	105,57 €	174,27 €
PSG3.0-29	PSG3.0-29H	29	87	93	18	70	0.173 - 0.067	91,62	335,93	2,171	109,92 €	181,40 €
PSG3.0-30	PSG3.0-30H	30	90	96	18	70	0.173 - 0.067	104,25	356,63	2,268	113,91 €	187,96 €
PSG3.0-32	PSG3.0-32H	32	96	102	18	70	0.173 - 0.067	111,20	380,40	2,473	122,19 €	201,65 €
PSG3.0-35	PSG3.0-35H	35	105	111	18	70	0.173 - 0.067	121,63	416,07	2,805	141,54 €	233,60 €
PSG3.0-38	PSG3.0-38H	38	114	120	18	70	0.173 - 0.067	132,05	451,73	3,167	151,94 €	250,69 €
PSG3.0-40	PSG3.0-40H	40	120	126	18	70	0.173 - 0.067	177,62	528,93	3,425	156,18 €	257,73 €

Dimensions in mm

Our other products



PDD

Actuating plunger,
Non-rotating detector
shaft



MLY_SS

Stainless steel bow
shackle with eye bolt,
Stainless steel



RCX-6

Spherical tilt washer -
DIN6319, convex



BPL

Ball transfer unit light
duty, Light



RJA00_02

Sealing strip, Clipping



RESC

Retractable castor for
aluminium profile,
Retractable castor



TCL-ECL

Adjusting nut, Fine
thread



M

Bellows cover,
Accessory:



MAC

Carabiner DIN5299
steel, Steel



PSG08S

Spur gear - precision
range, Stainless steel
316



SHW

Plain washer, Steel



MSP3815

Masterplate®
glueable insert
rectangular,
rectangular with nut

Complementary products



PSG3

Spur gear - precision
range, Case hardened
steel 20NCD2



PSG3S

Spur gear - precision
range, Stainless steel
303