


- For square tube $\square 25 \times 25$
- Material: rigid and flexible PVC

Info.


- Panel thickness (X) should be between 5 and 8mm

Accessories

- Structural tube **TUBE**
- Panel stop **BUT**
- Panel holder **BRI**

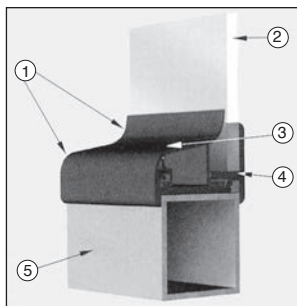

Typical application

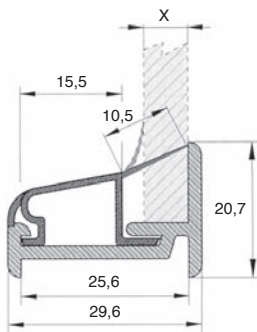

- 1) Flexible PVC element
- 2) Panel
- 3) Upper profile
- 4) Lower profile
- 5) Square tube

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Length (mm)	Weight (kg)	Stock*	Price each 1 to 4
PSP-25	3000	0,27	✓	57,49 €

*Depending on availability - Dimensions in mm

Our other products



TBE16
Economic mini-table
with trapezoidal
leadscrew, 5kg




VPRA_M
Handwheel with
handle,
Thermosetting plastic
- galvanised steel hub



BPPss
Pressed stainless
steel pillow block,
Stainless steel




DOG316
Motor-gearbox 12V
and 24V DC, from 1.5
to 2 Nm

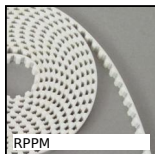

RPPM
RPP type belt per
metre, RPP14 Steel
cored polyurethane



INO
Internal gear,
Machined plastic
(delrin)

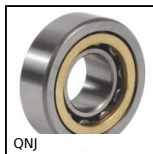

QNJ
Single row cylindrical
roller bearing, Single
flange on inner ring



ACL-PLAngle
Joining plate for
aluminium profile,
Angle connection



CLASS
Stainless steel
indexing handle -
male, Stainless steel



ABL100005
Antistatic brush,
Standard



HBM
Adjustment bushing
for half-rail guide,
Adjustment bushing



BH01
Single housed
bearing, Bearing fitted
with adhesive

Complementary products



BRI
Panel holder, Panel
holder



BUT
Panel stop, Panel stop



NCT
Square tube
connector, Fixed
angle



NCT
Square tube
connector, Fixed
angle