

Conical flexible shaft handle Ø20

New

PSPE20


For shafts Ø6 to Ø12

Conical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

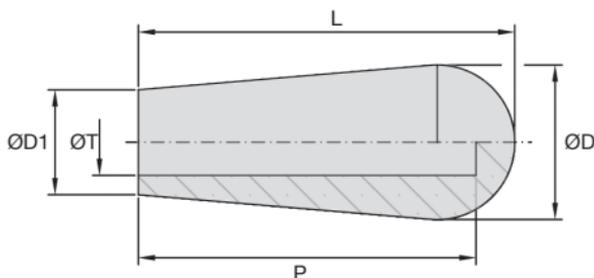

DISCOUNTS

| | | | | |
|------------|-----|------|------------|------|
| Qty | 1+ | 60+ | 100+ | 200+ |
| Disc. List | -5% | -10% | On request | |

| Part number | ØD | ØD1 | ØT | L | P | Weight (g) | Price each 1 to 59 |
|--------------|----|-----|----|----|----|------------|--------------------|
| PSPE20-43-6 | 20 | 14 | 6 | 43 | 40 | 11 | 1,78 € |
| PSPE20-43-7 | 20 | 14 | 7 | 43 | 40 | 10 | 1,68 € |
| PSPE20-43-8 | 20 | 14 | 8 | 43 | 40 | 10 | 1,62 € |
| PSPE20-43-10 | 20 | 14 | 10 | 43 | 40 | 9 | 1,56 € |
| PSPE20-43-12 | 20 | 14 | 12 | 43 | 40 | 8 | 1,50 € |

Dimensions in mm

New

Conical flexible shaft handle Ø22


For shafts Ø7 to Ø14

PSPE22**Conical handle**

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

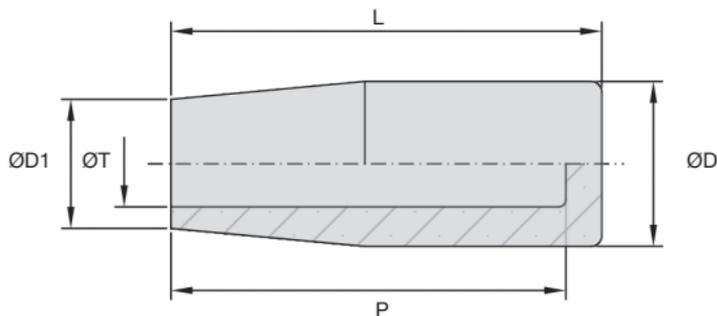**DISCOUNTS**

| | | | | |
|-------------------|----|-----|------|------------|
| Qty | 1+ | 60+ | 100+ | 200+ |
| Disc. List | | -5% | -10% | On request |

| Part number | ØD | ØD1 | ØT | L | P | Weight (g) | Price each 1 to 59 |
|--------------|----|-----|----|----|----|------------|--------------------|
| PSPE22-60-7 | 22 | 17 | 7 | 60 | 58 | 24 | 2,82 € |
| PSPE22-60-8 | 22 | 17 | 8 | 60 | 58 | 23 | 2,63 € |
| PSPE22-60-9 | 22 | 17 | 9 | 60 | 58 | 23 | 2,54 € |
| PSPE22-60-10 | 22 | 17 | 10 | 60 | 58 | 22 | 2,48 € |
| PSPE22-60-12 | 22 | 17 | 12 | 60 | 58 | 21 | 2,36 € |
| PSPE22-60-14 | 22 | 17 | 14 | 60 | 58 | 20 | 2,30 € |

Dimensions in mm

Flexible tube handle

Stock

PSPD18

For tubes Ø12 to Ø22

Knurled cylindrical handle


- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly


- Fit using a mallet, no adhesive required

Advantages

- Ergonomic handle for excellent grip

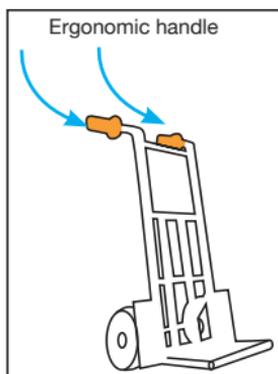

Typical application

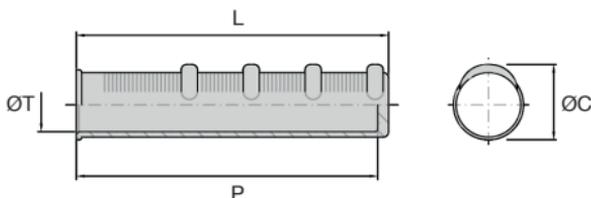

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 60+ | 100+ | 200+ |
| Disc. | List | -5% | -10% | On request |

| Part number | L | ØT | ØC | P | Weight (g) | Stock* | Price each |
|----------------|-----|----|----|-----|------------|---------|------------|
| | | | | | | 1 to 59 | |
| PSPD18-118-12 | 118 | 12 | 28 | 113 | 52 | ✓ | 4,31 € |
| PSPD18-118-14 | 118 | 14 | 28 | 113 | 45 | - | 4,00 € |
| PSPD18-118-16 | 118 | 16 | 28 | 113 | 40 | ✓ | 3,61 € |
| PSPD18-118-18 | 118 | 18 | 28 | 113 | 35 | ✓ | 3,24 € |
| PSPD18-118-20 | 118 | 20 | 28 | 113 | 28 | ✓ | 2,48 € |
| PSPD18-118-21 | 118 | 21 | 28 | 113 | 26 | - | 2,30 € |
| PSPD18-118-22 | 118 | 22 | 28 | 113 | 22 | ✓ | 2,11 € |
| PSPD18-118-22L | 118 | 22 | 28 | 113 | 19 | - | 2,17 € |

*Depending on availability - Dimensions in mm

Knurled cylindrical handle



- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

Advantages

- Ergonomic handle for excellent grip

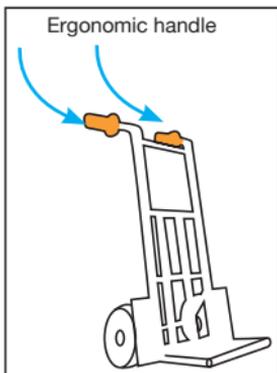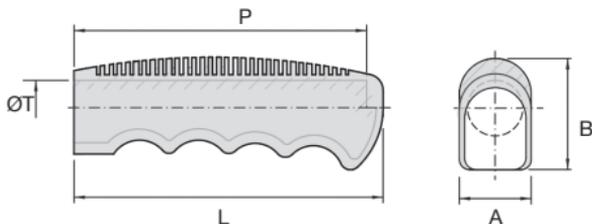

Typical application

DISCOUNTS

| | | | | |
|-------------------|----|-----|------|------------|
| Qty | 1+ | 60+ | 100+ | 200+ |
| Disc. List | | -5% | -10% | On request |

| Part number | L | A | B | ØT | P | Weight (g) | Stock* | Price each 1 to 59 |
|---------------|-----|----|----|----|-----|------------|--------|--------------------|
| PSPD40-112-18 | 112 | 26 | 40 | 18 | 106 | 49 | ✓ | 4,68 € |
| PSPD40-112-22 | 112 | 26 | 40 | 22 | 106 | 47 | ✓ | 4,68 € |

*Depending on availability - Dimensions in mm

Flexible tube handle



PSPT

For Ø18 - Ø33 tubes


- Tube handle with collar
- Smooth interior
- Material:
Black PVC

Assembly


- Fit using a mallet,
no adhesive required

Advantages

- Resists oil, shocks and low temperatures
- Good grip

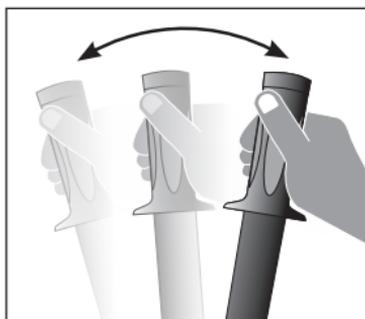

Typical application

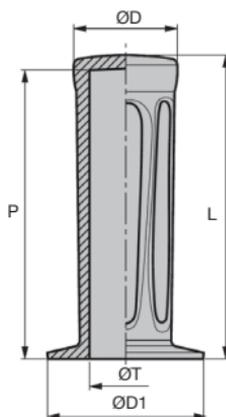

DISCOUNTS

| Qty | 1+ | 60+ | 100+ | 200+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |


| Part number | Tube ØT | L | ØD | ØD1 | P | Weight (g) | Stock* | Price each 1 to 59 |
|-------------|------------|-----|----|-----|-----|---------------|--------|-----------------------|
| PSPT18-115 | 18-19 | 115 | 31 | 44 | 110 | 62 | ✓ | 3,22 € |
| PSPT20-115 | 20-21 | 115 | 31 | 44 | 110 | 56 | ✓ | 2,84 € |
| PSPT22-115 | 22-23 | 115 | 31 | 44 | 110 | 46 | ✓ | 2,46 € |
| PSPT24-125 | 24-25 | 125 | 36 | 49 | 120 | 72 | ✓ | 3,67 € |
| PSPT26-125 | 26 | 125 | 36 | 49 | 120 | 60 | ✓ | 3,22 € |
| PSPT27-125 | 27-28 | 125 | 36 | 49 | 120 | 50 | ✓ | 3,10 € |
| PSPT29-125 | 29 | 125 | 36 | 49 | 120 | 50 | ✓ | 3,10 € |
| PSPT30-130 | 30 | 130 | 42 | 51 | 125 | 92 | ✓ | 3,67 € |
| PSPT33-130 | 33 | 130 | 42 | 51 | 125 | 74 | ✓ | 3,22 € |

*Depending on availability - Dimensions in mm

- Material: black technopolymer

Info.

- Dimensions are given as a guide and are subject to change
- Not sold individually, please contact us for details

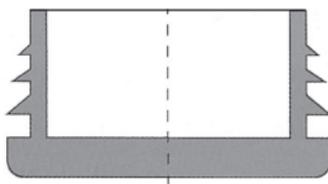

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 60+ | 100+ | 200+ |
| Disc. | List | -5% | -10% | On request |

| Part number | External tube Ø | Tube thickness | Stock* | Price each 1 to 59 | Part number | External tube Ø | Tube thickness | Stock* | Price each 1 to 59 |
|-------------|-----------------|----------------|--------|--------------------|---------------|-----------------|----------------|--------|--------------------|
| BPTR-10 | 10 | 1-2 | ✓ | 0,17 € | BPTR-40 | 40 | 1-3 | ✓ | 1,11 € |
| BPTR-12 | 12 | 1-2 | ✓ | 0,17 € | BPTR-42/1-2 | 42 | 1-2 | ✓ | 1,24 € |
| BPTR-13 | 13 | 1-2 | - | 0,17 € | BPTR-42/3-6 | 42 | 3-6 | - | 1,32 € |
| BPTR-14 | 14 | 1-2 | ✓ | 0,22 € | BPTR-45 | 45 | 1-3 | ✓ | 2,19 € |
| BPTR-15 | 15 | 1-2 | ✓ | 0,34 € | BPTR-48 | 48 | 1,2-3,6 | ✓ | 2,19 € |
| BPTR-16 | 16 | 1-2 | ✓ | 0,22 € | BPTR-50 | 50 | 1-2,5 | ✓ | 2,19 € |
| BPTR-18 | 18 | 1-2 | ✓ | 0,27 € | BPTR-52 | 52 | 1,5-3,5 | - | 2,43 € |
| BPTR-19 | 19 | 1-2,5 | - | 0,24 € | BPTR-55 | 55 | 1-3 | - | 2,59 € |
| BPTR-20 | 20 | 1-2,5 | ✓ | 0,27 € | BPTR-60/1,5-3 | 60 | 1,5-3 | ✓ | 3,19 € |
| BPTR-21 | 21 | 1-2 | ✓ | 0,27 € | BPTR-60/3-5 | 60 | 3-5 | - | 3,29 € |
| BPTR-22 | 22 | 1-2 | - | 0,27 € | BPTR-65 | 65 | 1,5-3,5 | - | 3,35 € |
| BPTR-23 | 23 | 1-2,5 | - | 0,27 € | BPTR-70 | 70 | 1-3,5 | - | 3,43 € |
| BPTR-25 | 25 | 1-3 | ✓ | 0,34 € | BPTR-76 | 76 | 1,6-4 | ✓ | 3,89 € |
| BPTR-27 | 27 | 1-3 | ✓ | 0,45 € | BPTR-80 | 80 | 1,5-3 | - | 4,02 € |
| BPTR-28 | 28 | 1-2 | ✓ | 0,45 € | BPTR-90 | 90 | 1,5-5 | - | 6,39 € |
| BPTR-30 | 30 | 1-2,5 | ✓ | 0,57 € | BPTR-95 | 95 | 1,5-4 | - | 9,17 € |
| BPTR-32 | 32 | 1-3 | - | 0,70 € | BPTR-100 | 100 | 2-4,5 | - | 7,01 € |
| BPTR-34 | 34 | 1-3 | ✓ | 0,76 € | BPTR-102 | 102 | 2-4 | - | 7,27 € |
| BPTR-35 | 35 | 1-3 | - | 0,92 € | BPTR-105 | 105 | 2-4,5 | - | 7,63 € |
| BPTR-36 | 36 | 1-3 | ✓ | 0,92 € | BPTR-110 | 110 | 2-4,5 | - | 8,50 € |
| BPTR-38 | 38 | 1-3 | ✓ | 0,98 € | BPTR-120 | 120 | 2-4 | - | 10,32 € |

*Depending on availability - Dimensions in mm