

Flexible tube handle



PSPT

For Ø18 - Ø33 tubes


- Tube handle with collar
- Smooth interior
- Material:
Black PVC

Assembly


- Fit using a mallet,
no adhesive required

Advantages

- Resists oil, shocks and low temperatures

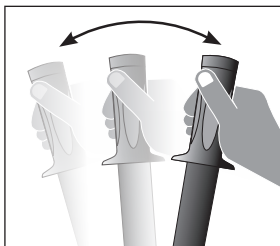

Typical application

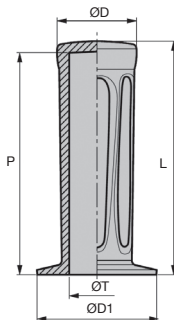

DISCOUNTS

| Qty | 1+ | 60+ | 100+ | 200+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | Tube | | ØD | ØD1 | P | Weight (g) | Stock* | Price each 1 to 59 |
|-------------|-------|-----|----|-----|-----|------------|--------|--------------------|
| | ØT | L | | | | | | |
| PSPT18-115 | 18-19 | 115 | 31 | 44 | 110 | 62 | ✓ | 3,15 € |
| PSPT20-115 | 20-21 | 115 | 31 | 44 | 110 | 56 | ✓ | 2,79 € |
| PSPT22-115 | 22-23 | 115 | 31 | 44 | 110 | 46 | ✓ | 2,42 € |
| PSPT24-125 | 24-25 | 125 | 36 | 49 | 120 | 72 | ✓ | 3,60 € |
| PSPT26-125 | 26 | 125 | 36 | 49 | 120 | 60 | ✓ | 3,15 € |
| PSPT27-125 | 27-28 | 125 | 36 | 49 | 120 | 50 | ✓ | 3,03 € |
| PSPT29-125 | 29 | 125 | 36 | 49 | 120 | 50 | ✓ | 3,03 € |
| PSPT30-130 | 30 | 130 | 42 | 51 | 125 | 92 | ✓ | 3,60 € |
| PSPT33-130 | 33 | 130 | 42 | 51 | 125 | 74 | ✓ | 3,15 € |

*Depending on availability - Dimensions in mm

Conical flexible shaft handle Ø20

For shafts Ø6 to Ø12


PSPE20

Conical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

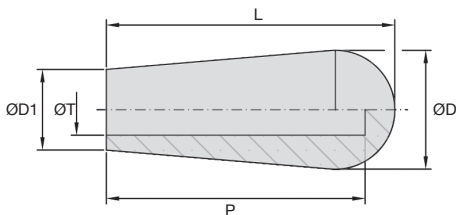

DISCOUNTS

| | | | | |
|------------|-----|------|------------|------|
| Qty | 1+ | 60+ | 100+ | 200+ |
| Disc. List | -5% | -10% | On request | |

| Part number | ØD | ØD1 | ØT | L | P | Weight (g) | Stock* | Price each 1 to 59 |
|--------------|----|-----|----|----|----|------------|--------|--------------------|
| PSPE20-43-6 | 20 | 14 | 6 | 43 | 40 | 11 | - | 1,74 € |
| PSPE20-43-7 | 20 | 14 | 7 | 43 | 40 | 10 | - | 1,65 € |
| PSPE20-43-8 | 20 | 14 | 8 | 43 | 40 | 10 | - | 1,59 € |
| PSPE20-43-10 | 20 | 14 | 10 | 43 | 40 | 9 | - | 1,53 € |
| PSPE20-43-12 | 20 | 14 | 12 | 43 | 40 | 8 | - | 1,47 € |

*Depending on availability - Dimensions in mm

HPC

CAT NEW
01/2023

www.hpceurope.com

Tel. +33(0)4 37 496 496

Conical flexible shaft handle Ø22

PSPE22


For shafts Ø7 to Ø14

Conical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

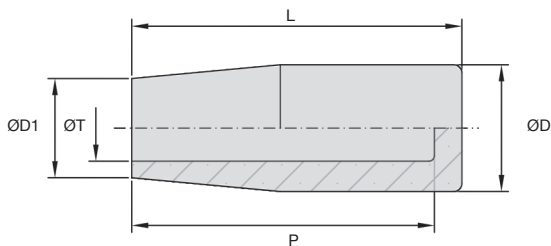

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 60+ | 100+ | 200+ |
| Disc. | List | -5% | -10% | On request |

| Part number | ØD | ØD1 | ØT | L | P | Weight (g) | Stock* | Price each |
|--------------|----|-----|----|----|----|------------|---------|------------|
| | | | | | | | 1 to 59 | |
| PSPE22-60-7 | 22 | 17 | 7 | 60 | 58 | 24 | - | 2,76 € |
| PSPE22-60-8 | 22 | 17 | 8 | 60 | 58 | 23 | - | 2,58 € |
| PSPE22-60-9 | 22 | 17 | 9 | 60 | 58 | 23 | - | 2,49 € |
| PSPE22-60-10 | 22 | 17 | 10 | 60 | 58 | 22 | - | 2,43 € |
| PSPE22-60-12 | 22 | 17 | 12 | 60 | 58 | 21 | - | 2,31 € |
| PSPE22-60-14 | 22 | 17 | 14 | 60 | 58 | 20 | - | 2,25 € |

*Depending on availability - Dimensions in mm

Flexible tube handle

For tubes Ø12 to Ø22

PSPD18

Knurled cylindrical handle


- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly


- Fit using a mallet, no adhesive required

Advantages

- Ergonomic handle for excellent grip

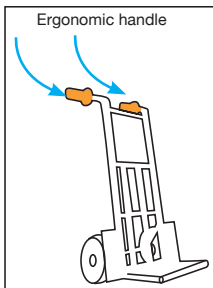

Typical application

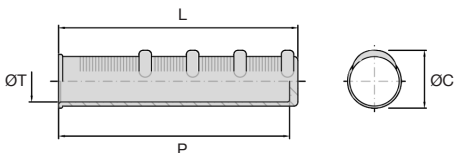

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 60+ | 100+ | 200+ |
| Disc. | List | -5% | -10% | On request |

| Part number | L | ØT | ØC | P | Weight (g) | Stock* | Price each 1 to 59 |
|----------------|-----|----|----|-----|------------|--------|--------------------|
| PSPD18-118-12 | 118 | 12 | 28 | 113 | 52 | - | 4,14 € |
| PSPD18-118-14 | 118 | 14 | 28 | 113 | 45 | - | 3,84 € |
| PSPD18-118-16 | 118 | 16 | 28 | 113 | 40 | - | 3,54 € |
| PSPD18-118-18 | 118 | 18 | 28 | 113 | 35 | - | 3,18 € |
| PSPD18-118-20 | 118 | 20 | 28 | 113 | 28 | - | 2,43 € |
| PSPD18-118-21 | 118 | 21 | 28 | 113 | 26 | - | 2,25 € |
| PSPD18-118-22 | 118 | 22 | 28 | 113 | 22 | - | 2,07 € |
| PSPD18-118-22L | 118 | 22 | 28 | 113 | 19 | - | 2,13 € |

*Depending on availability - Dimensions in mm

Flexible tube handle

PSPD40

For tubes Ø18 and Ø22

Knurled cylindrical handle



- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

Advantages

- Ergonomic handle for excellent grip

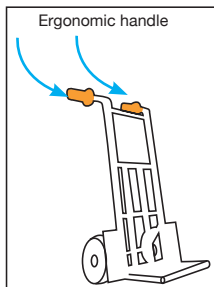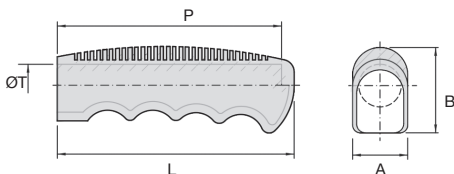

Typical application

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 60+ | 100+ | 200+ |
| Disc. | List | -5% | -10% | On request |

| Part number | L | A | B | ØT | P | Weight (g) | Stock* | Price each 1 to 59 |
|---------------|-----|----|----|----|-----|------------|--------|--------------------|
| PSPD40-112-18 | 112 | 26 | 40 | 18 | 106 | 49 | - | 4,59 € |
| PSPD40-112-22 | 112 | 26 | 40 | 22 | 106 | 47 | - | 4,59 € |

*Depending on availability - Dimensions in mm

Our other products



PM3

Worm and wheel set,
Machined plastic
(delrin)



F7-SN

Multifunction display,
Articulated support



PT821

Drive sprocket for slat
top chain, Ranges 821
and 805



LRR

Spring loaded latch,
Spring loaded latch



ZG1

Plastic spur gear,
Machined plastic
(delrin)



PAM_SS

Stainless steel
articulated levelling
foot, Ø 30 & 40



EBH

Cap nut Hygienic
Design®, With collar



BTE

Universal tension arm,
For standard
applications



FB_ECO

Eco. range steel bevel
gear, 4:1



GBS

Nut for ballscrew,
Flanged ballscrew nut



SH1

Parallel axis helical
gear, Steel 20NCD2



PRF_PL_9090

Joining plate for
aluminium profile,
Joint plate - 90x90
mm

Complementary products



PSPD18

Flexible tube handle,
Black PVC



PSPT

Flexible tube handle,
PVC



PSPD40

Flexible tube handle,
Black PVC



PSPE22

Conical flexible shaft
handle Ø22, Black
PVC