

Conical flexible shaft handle Ø20

New

PSPE20


For shafts Ø6 to Ø12

Conical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

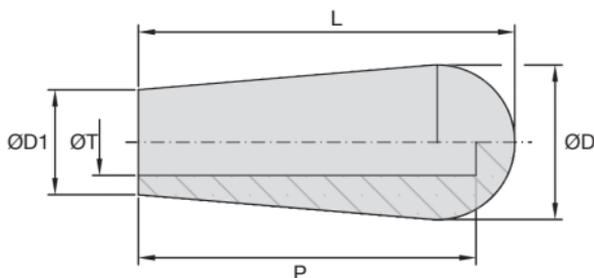

DISCOUNTS

Qty	1+	60+	100+	200+
Disc. List	-5%	-10%	On request	

Part number	ØD	ØD1	ØT	L	P	Weight (g)	Price each 1 to 59
PSPE20-43-6	20	14	6	43	40	11	1,78 €
PSPE20-43-7	20	14	7	43	40	10	1,68 €
PSPE20-43-8	20	14	8	43	40	10	1,62 €
PSPE20-43-10	20	14	10	43	40	9	1,56 €
PSPE20-43-12	20	14	12	43	40	8	1,50 €

Dimensions in mm

New

Conical flexible shaft handle Ø22


For shafts Ø7 to Ø14

PSPE22**Conical handle**

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

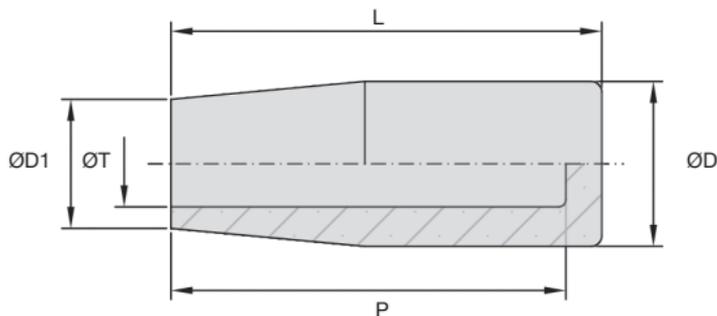**DISCOUNTS**

Qty	1+	60+	100+	200+
Disc. List		-5%	-10%	On request

Part number	ØD	ØD1	ØT	L	P	Weight (g)	Price each 1 to 59
PSPE22-60-7	22	17	7	60	58	24	2,82 €
PSPE22-60-8	22	17	8	60	58	23	2,63 €
PSPE22-60-9	22	17	9	60	58	23	2,54 €
PSPE22-60-10	22	17	10	60	58	22	2,48 €
PSPE22-60-12	22	17	12	60	58	21	2,36 €
PSPE22-60-14	22	17	14	60	58	20	2,30 €

Dimensions in mm

Flexible tube handle

Stock

PSPD18

For tubes $\varnothing 12$ to $\varnothing 22$

Knurled cylindrical handle


- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly


- Fit using a mallet, no adhesive required

Advantages

- Ergonomic handle for excellent grip

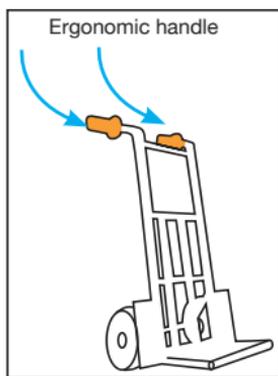

Typical application

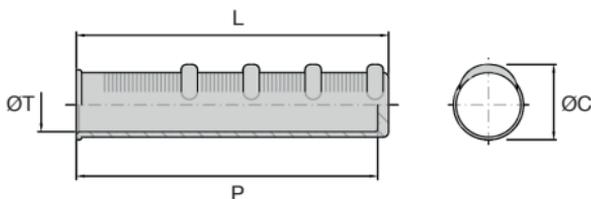

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	L	ØT	ØC	P	Weight (g)	Stock*	Price each
						1 to 59	
PSPD18-118-12	118	12	28	113	52	✓	4,31 €
PSPD18-118-14	118	14	28	113	45	-	4,00 €
PSPD18-118-16	118	16	28	113	40	✓	3,61 €
PSPD18-118-18	118	18	28	113	35	✓	3,24 €
PSPD18-118-20	118	20	28	113	28	✓	2,48 €
PSPD18-118-21	118	21	28	113	26	-	2,30 €
PSPD18-118-22	118	22	28	113	22	✓	2,11 €
PSPD18-118-22L	118	22	28	113	19	-	2,17 €

*Depending on availability - Dimensions in mm

Knurled cylindrical handle



- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

Advantages

- Ergonomic handle for excellent grip

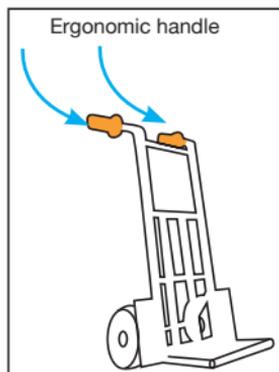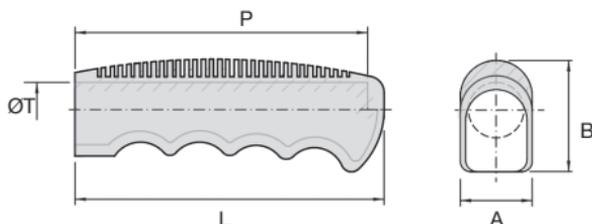

Typical application

DISCOUNTS

Qty	1+	60+	100+	200+
Disc. List	-5%	-10%	On request	

Part number	L	A	B	ØT	P	Weight (g)	Stock*	Price each
							1 to 59	
PSPD40-112-18	112	26	40	18	106	49	✓	4,68 €
PSPD40-112-22	112	26	40	22	106	47	✓	4,68 €

*Depending on availability - Dimensions in mm

Flexible tube handle



PSPT

For Ø18 - Ø33 tubes


- Tube handle with collar
- Smooth interior
- Material:
Black PVC

Assembly


- Fit using a mallet,
no adhesive required

Advantages

- Resists oil, shocks and low temperatures
- Good grip

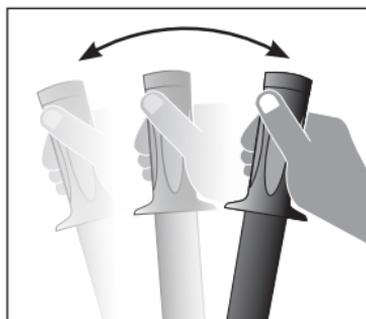

Typical application

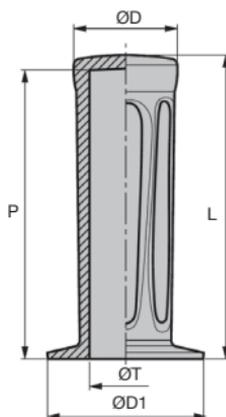

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request


Part number	Tube ØT	L	ØD	ØD1	P	Weight (g)	Stock*	Price each 1 to 59
PSPT18-115	18-19	115	31	44	110	62	✓	3,22 €
PSPT20-115	20-21	115	31	44	110	56	✓	2,84 €
PSPT22-115	22-23	115	31	44	110	46	✓	2,46 €
PSPT24-125	24-25	125	36	49	120	72	✓	3,67 €
PSPT26-125	26	125	36	49	120	60	✓	3,22 €
PSPT27-125	27-28	125	36	49	120	50	✓	3,10 €
PSPT29-125	29	125	36	49	120	50	✓	3,10 €
PSPT30-130	30	130	42	51	125	92	✓	3,67 €
PSPT33-130	33	130	42	51	125	74	✓	3,22 €

*Depending on availability - Dimensions in mm

- Material: black technopolymer

Info.

- Dimensions are given as a guide and are subject to change
- Not sold individually, please contact us for details

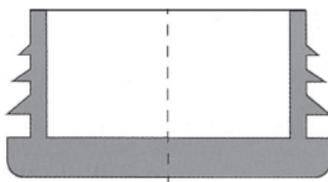

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	External tube Ø	Tube thickness	Stock*	Price each 1 to 59	Part number	External tube Ø	Tube thickness	Stock*	Price each 1 to 59
BPTR-10	10	1-2	✓	0,17 €	BPTR-40	40	1-3	✓	1,11 €
BPTR-12	12	1-2	✓	0,17 €	BPTR-42/1-2	42	1-2	✓	1,24 €
BPTR-13	13	1-2	-	0,17 €	BPTR-42/3-6	42	3-6	-	1,32 €
BPTR-14	14	1-2	✓	0,22 €	BPTR-45	45	1-3	✓	2,19 €
BPTR-15	15	1-2	✓	0,34 €	BPTR-48	48	1,2-3,6	✓	2,19 €
BPTR-16	16	1-2	✓	0,22 €	BPTR-50	50	1-2,5	✓	2,19 €
BPTR-18	18	1-2	✓	0,27 €	BPTR-52	52	1,5-3,5	-	2,43 €
BPTR-19	19	1-2,5	-	0,24 €	BPTR-55	55	1-3	-	2,59 €
BPTR-20	20	1-2,5	✓	0,27 €	BPTR-60/1,5-3	60	1,5-3	✓	3,19 €
BPTR-21	21	1-2	✓	0,27 €	BPTR-60/3-5	60	3-5	-	3,29 €
BPTR-22	22	1-2	-	0,27 €	BPTR-65	65	1,5-3,5	-	3,35 €
BPTR-23	23	1-2,5	-	0,27 €	BPTR-70	70	1-3,5	-	3,43 €
BPTR-25	25	1-3	✓	0,34 €	BPTR-76	76	1,6-4	✓	3,89 €
BPTR-27	27	1-3	✓	0,45 €	BPTR-80	80	1,5-3	-	4,02 €
BPTR-28	28	1-2	✓	0,45 €	BPTR-90	90	1,5-5	-	6,39 €
BPTR-30	30	1-2,5	✓	0,57 €	BPTR-95	95	1,5-4	-	9,17 €
BPTR-32	32	1-3	-	0,70 €	BPTR-100	100	2-4,5	-	7,01 €
BPTR-34	34	1-3	✓	0,76 €	BPTR-102	102	2-4	-	7,27 €
BPTR-35	35	1-3	-	0,92 €	BPTR-105	105	2-4,5	-	7,63 €
BPTR-36	36	1-3	✓	0,92 €	BPTR-110	110	2-4,5	-	8,50 €
BPTR-38	38	1-3	✓	0,98 €	BPTR-120	120	2-4	-	10,32 €

*Depending on availability - Dimensions in mm