



Flexible tube handle

For Ø18 - Ø33 tubes

PSPT


- Tube handle with collar
- Smooth interior
- Material:
Black PVC

Assembly


- Fit using a mallet, no adhesive required

Advantages

- Resists oil, shocks and low temperatures

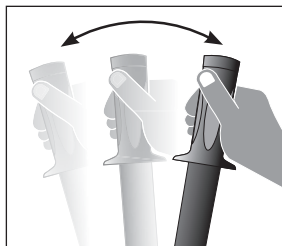

Typical application

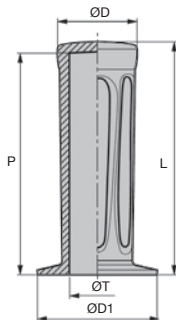

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Tube ØT	L	ØD	ØD1	P	Weight (g)	Price each 1 to 59
PSPT18-115	18-19	115	31	44	110	62	2,69 €
PSPT20-115	20-21	115	31	44	110	56	2,38 €
PSPT22-115	22-23	115	31	44	110	46	2,06 €
PSPT24-125	24-25	125	36	49	120	72	3,07 €
PSPT26-125	26	125	36	49	120	60	2,69 €
PSPT27-125	27-28	125	36	49	120	50	2,60 €
PSPT29-125	29	125	36	49	120	50	2,60 €
PSPT30-130	30	130	42	51	125	92	3,07 €
PSPT33-130	33	130	42	51	125	74	2,69 €

Dimensions in mm

Our other products



RURp

Fixed castor with plate, Polyurethane - Aluminium rim (Free running)



PPD

Indexing plunger for sheets, For sheet metal



PGT

Sliding profile, Sliding panel support



CHAE4060PA

Decorative asymmetric screwed hinge, Polyamide



AFSE

Locking pin with interlocking safety latch, with interlocking safety...




G3-ECO

Eco range Spur gear, Steel C45



HG8-ECO

Eco range Spur gear, Steel C45

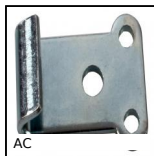

AC

Strike for toggle latch, 15mm



CHM110

Worm and wheel gear reducer, up to 980 Nm



UGH50

H Type Guide units, For Ø50 actuators



RPB

Ballscrew bearing unit, Support



RBGtc

Swivel castor with central hole, Steel - grey rubber

Complementary products



PSPD18

Flexible tube handle, Black PVC



PSPD40

Flexible tube handle, Black PVC



PSP22

Conical flexible shaft handlee Ø22, Black PVC



PSPE20

Conical flexible shaft handle Ø20, Black PVC