



Flexible tube handle

For Ø18 - Ø33 tubes

PSPT


- Tube handle with collar
- Smooth interior
- Material:
Black PVC

Assembly


- Fit using a mallet, no adhesive required

Advantages

- Resists oil, shocks and low temperatures

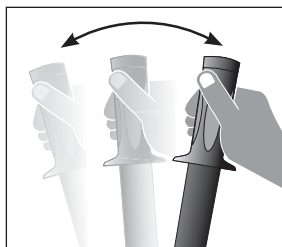

Typical application

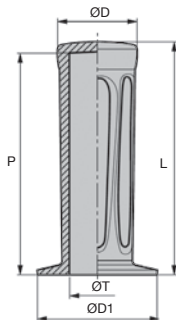

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Tube ØT	L	ØD	ØD1	P	Weight (g)	Price each 1 to 59
PSPT18-115	18-19	115	31	44	110	62	2,69 €
PSPT20-115	20-21	115	31	44	110	56	2,38 €
PSPT22-115	22-23	115	31	44	110	46	2,06 €
PSPT24-125	24-25	125	36	49	120	72	3,07 €
PSPT26-125	26	125	36	49	120	60	2,69 €
PSPT27-125	27-28	125	36	49	120	50	2,60 €
PSPT29-125	29	125	36	49	120	50	2,60 €
PSPT30-130	30	130	42	51	125	92	3,07 €
PSPT33-130	33	130	42	51	125	74	2,69 €

Dimensions in mm

Our other products



UCP_PBT
Stainless/Polymer
pillow block bearing,
Polymer and stainless
steel




SLBWSS
Indexing plunger,
weldable, Weldable -
Stainless steel



PM2
Worm and wheel set,
Hardened steel



NTMbr
Set screw brass tip,
Brass-point

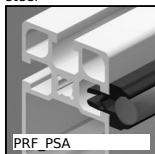

PRF_PSA
Shaft support for
aluminium profile,
Shaft support



RT61ss
Self-centering locking
Assembly,
Medium/low torque



VQT
Quarter-turn clamp
lock, Plastic or
stainless steel button



D19 D29
Compression springs
in metre length
stainless steel, by the
metre



SCE
U-shaped cable
clamp, Steel



RFVbr
Stainless steel
reaction arm,
Reaction arm



PRF4590
Standard aluminium
profile, 45 x 90 mm



FF10
Offset spur gear
reducer, from 0.78 to
3.70 Nm

Complementary products



PSPD18
Flexible tube handle,
Black PVC



PSPD40
Flexible tube handle,
Black PVC



PSPE22
Conical flexible shaft
handlee Ø22, Black
PVC



PSPE20
Flexible shaft
handle Ø20, Black
PVC