



Flexible tube handle

For Ø18 - Ø33 tubes

PSPT


- Tube handle with collar
- Smooth interior
- Material:
Black PVC

Assembly


- Fit using a mallet, no adhesive required

Advantages

- Resists oil, shocks and low temperatures

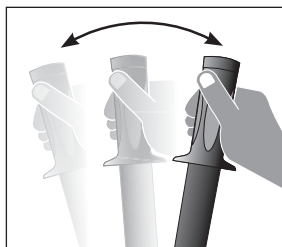

Typical application

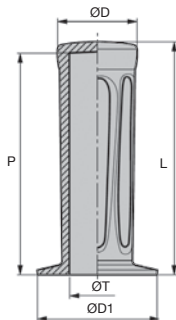

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Tube ØT	L	ØD	ØD1	P	Weight (g)	Price each 1 to 59
PSPT18-115	18-19	115	31	44	110	62	2,69 €
PSPT20-115	20-21	115	31	44	110	56	2,38 €
PSPT22-115	22-23	115	31	44	110	46	2,06 €
PSPT24-125	24-25	125	36	49	120	72	3,07 €
PSPT26-125	26	125	36	49	120	60	2,69 €
PSPT27-125	27-28	125	36	49	120	50	2,60 €
PSPT29-125	29	125	36	49	120	50	2,60 €
PSPT30-130	30	130	42	51	125	92	3,07 €
PSPT33-130	33	130	42	51	125	74	2,69 €

Dimensions in mm

Our other products



PGR

Folding revolving handle for handwheel, Folding



KSTM

Igubal® pillow block bearing, Polymer



RPCplss

Fixed castor with plate, Stainless steel - Polyamide



UCFL_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel



TAC_SS

Stainless steel rigging screw (hook/eye), Stainless steel



BLH70

Right angled gearbox, from 26 to 128 Nm



 
SBS_M

Single chain supplied by the metre, Stainless steel



DB_ECO

Eco. range steel bevel gear, 2:1



G1

Steel spur gear, Steel 20NCD2



CDPC

Flanged drill bushing, Steel



CAP880

Side flexing slim slat top chain acetal, Narrow range 880



PRF-SCREEN-4

Screen support, Support with 4 axes of rotation

Complementary products




PSPD18

Flexible tube handle, Black PVC



PSPD40

 Flexible tube handle, Black PVC



PSPE22

Conical flexible shaft handlee Ø22, Black PVC



PSPE20

Conical flexible shaft handle Ø20, Black PVC