



# Flexible tube handle

For Ø18 - Ø33 tubes

PSPT


- Tube handle with collar
- Smooth interior
- Material:  
Black PVC

## Assembly


- Fit using a mallet, no adhesive required

## Advantages

- Resists oil, shocks and low temperatures

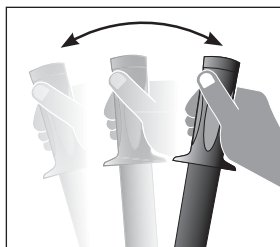

Typical application

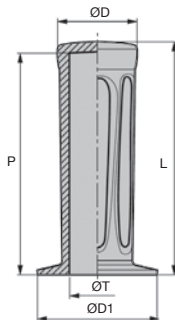

## DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Tube ØT	L	ØD	ØD1	P	Weight (g)	Price each 1 to 59
PSPT18-115	18-19	115	31	44	110	62	2,69 €
PSPT20-115	20-21	115	31	44	110	56	2,38 €
PSPT22-115	22-23	115	31	44	110	46	2,06 €
PSPT24-125	24-25	125	36	49	120	72	3,07 €
PSPT26-125	26	125	36	49	120	60	2,69 €
PSPT27-125	27-28	125	36	49	120	50	2,60 €
PSPT29-125	29	125	36	49	120	50	2,60 €
PSPT30-130	30	130	42	51	125	92	3,07 €
PSPT33-130	33	130	42	51	125	74	2,69 €

Dimensions in mm

## Our other products



DOMI50  
Accessories, Clamping lever



BPTR\_M  
End cap with threaded insert for round tube, With threaded insert



BL8  
Right angled gearbox, from 0.20 to 2 Nm



SVT15  
Screwjack with travelling screw, with translating screw



PW\_PWG15  
Worm - precision range, Steel



DOMI120  
Accessories, Turntable




PCF2  
Conical flexible mount, Oval base plate




F7-P-AM  
Multifunction display, Magnetic band



 CHASb89  
Hinge without pin, Plastic hinge



 ACL-PR  
Joining plate for aluminium profile, Right angled



MF  
Shock Absorber -universal flange, Universal fixing



RPCpl  
Fixed castor with plate, Steel - Polyamide

## Complementary products



PSPD18  
Flexible tube handle, Black PVC



PSPD40  
Flexible tube handle, Black PVC



PSP22  
Conical flexible shaft handlee Ø22, Black PVC



PSP20  
Conical flexible shaft handle Ø20, Black PVC