



Flexible tube handle

For Ø18 - Ø33 tubes

PSPT


- Tube handle with collar
- Smooth interior
- Material:
Black PVC

Assembly


- Fit using a mallet, no adhesive required

Advantages

- Resists oil, shocks and low temperatures

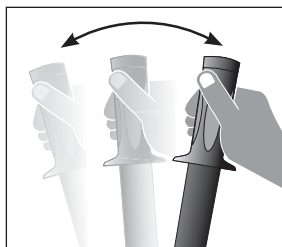

Typical application

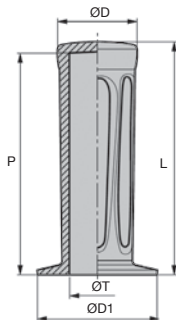

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Tube ØT	L	ØD	ØD1	P	Weight (g)	Price each 1 to 59
PSPT18-115	18-19	115	31	44	110	62	2,69 €
PSPT20-115	20-21	115	31	44	110	56	2,38 €
PSPT22-115	22-23	115	31	44	110	46	2,06 €
PSPT24-125	24-25	125	36	49	120	72	3,07 €
PSPT26-125	26	125	36	49	120	60	2,69 €
PSPT27-125	27-28	125	36	49	120	50	2,60 €
PSPT29-125	29	125	36	49	120	50	2,60 €
PSPT30-130	30	130	42	51	125	92	3,07 €
PSPT33-130	33	130	42	51	125	74	2,69 €

Dimensions in mm

Our other products



DOMI30

Accessories, Turntable



RT70

Self-centering locking
Assembly,
Medium/high torque



LRR22

Small dimension latch
with locking system,
Aluminium



T2,5-BAR

T type tooth bar
stock, T2.5



 
BOX-INS-W

Box set of self tapping
inserts, Boxed set -
For wood



SSB

Stainless steel bevel
gear, 1:1



RPP14

RPP heavy duty
timing belt, RPP14



P60

Worm and wheel gear
reducer, up to 118
Nm



 
HW_HT

Half-rail guide, Rail



VPSS

Small 6 lobe threaded
handle - male,



NANO

Speed controller 3A, 3
A



GLT3-46

Telescopic drawer,

Complementary products



PSPD18

Flexible tube handle,
Black PVC



PSPD40

Flexible tube handle,
Black PVC



PSPE22

Conical flexible shaft
handlee Ø22, Black
PVC



PSPE20

Conical flexible shaft
handlee Ø20, Black
PVC