


- For driving CAP820 and CAP815 plate chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

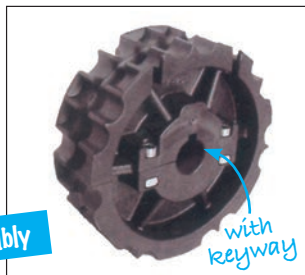

Two part design

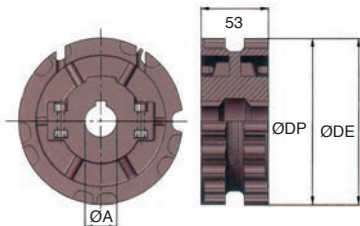

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT820-21-25	21	129	129,26	25	0,4	30,67 €
PT820-21-30	21	129	129,26	30	0,4	30,67 €
PT820-21-35	21	129	129,26	35	0,4	30,67 €
PT820-21-40	21	129	129,26	40	0,4	30,67 €
PT820-21-45	21	129	129,26	45	0,4	30,67 €
PT820-23-25	23	141	141,22	25	0,5	32,38 €
PT820-23-30	23	141	141,22	30	0,5	32,38 €
PT820-23-35	23	141	141,22	35	0,5	32,38 €
PT820-23-40	23	141	141,22	40	0,5	32,38 €
PT820-23-45	23	141	141,22	45	0,5	32,38 €
PT820-25-25	25	153	153,20	25	0,5	32,71 €
PT820-25-30	25	153	153,20	30	0,5	32,71 €
PT820-25-35	25	153	153,20	35	0,5	32,71 €
PT820-25-40	25	153	153,20	40	0,5	32,71 €
PT820-25-45	25	153	153,20	45	0,5	32,71 €

Dimensions in mm

Our other products



GE
Toggle latches,
Standard



DH
Dowel pin, Solid DIN
6325



BFM2
Flanged bronze nut,
Bronze - 2 threads



CHA35
Hinge for aluminium
profile, Hinge



BSM_LOK
Long-Lok spring
plunger with internal
hexagonal socket,
LONG-LOK - s...



CHALss
Piano hinge, Stainless
steel



NJM
Multiple junction
clamp, Multiple



PR125rehausse
Extension for
articulated foot Ø123,
articulated foot PR125



CHNrb
Warning chain with
red and white links,
Steel



ADL_M
Male eye bolt
conforms to DIN580,
Steel



DB
Steel bevel gear, 2:1



T5M_T10M
T type timing belt per
metre, T5 Steel cored
polyurethane

Complementary products



CAP820
Slim slat top chain
acetal, Narrow
straight range 820



CAP815
Slim slat top chain
stainless steel,
Narrow range 815



DBL820
Idler for slat top
chain, Ranges 820
and 815



BAP25
Plastic clamping
collar, Ø25 - Ø40