



# Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


## Advantage

- Two part design facilitates easy assembly

Easy assembly

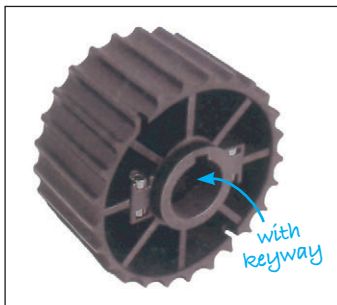

Two part design

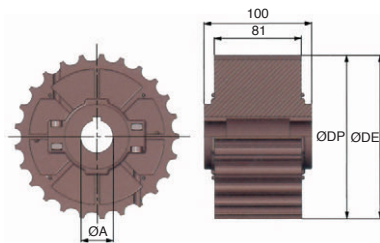

## DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT821-25-30	25	153	153,2	30	0,9	70,12 €
PT821-25-35	25	153	153,2	35	0,9	70,12 €
PT821-25-40	25	153	153,2	40	0,9	70,12 €
PT821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

## Our other products




PR821

Idler sprocket for slat top chain, Ranges 821 and 805



PRES7HR

Manual workbench press, Force up to 700kg

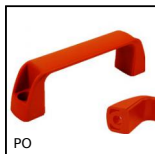

PO

Pull handle - Multi-sector, Smooth hole



UCF\_55

Stainless steel flanged bearing, Stainless steel



FDSQ

Flexible drive shaft, Masterflex® Steel, with PVC casing



HW\_HT

Half-rail guide, Wheel



WSS

Symmetrical S shaped hook, Steel



PTA80

Articulated levelling foot, pressed base Ø80, Ø 80



AK

Bellows coupling Gerwah®, from 36 to 100



LRM2

Cylindrical bronze nut, Bronze - 2 threads



F7-SF-SM

Multifunction display, Mounting bracket for



MDPOT

Potentiometer,

## Complementary products



CAP821

Slat top chain acetal, Large range 821



CAP805

Slat top chain stainless steel, Large range 805