



# Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


## Advantage

- Two part design facilitates easy assembly

Easy assembly

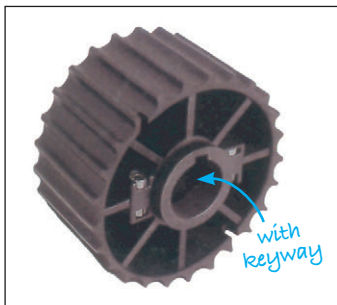

Two part design

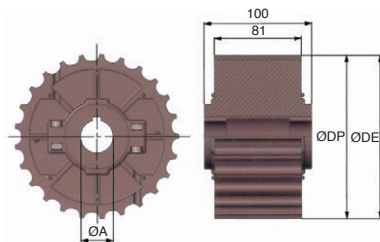

## DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT821-25-30	25	153	153,2	30	0,9	70,12 €
PT821-25-35	25	153	153,2	35	0,9	70,12 €
PT821-25-40	25	153	153,2	40	0,9	70,12 €
PT821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

## Our other products



ACLALF

Adjustable foot for aluminium profile, Ideal for workstations



RPCplss

Swivel castor with double brake, Stainless steel - Polyamide



HTD5M-BAR

HTD type tooth bar stock, HTD5



BLHB60

Right angled gearbox, bored shafts, up to 70 Nm



PENC

Recessed handle, clip-in




CAP882

Flexible slat top chain acetal, Large range 882



CAP815

Slim slat top chain stainless steel, Narrow range 815

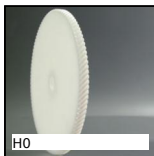

H0

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



PRF\_FIX\_ANG

Fastener for aluminium profile, Angular joint



ZHG6

Plastic spur gear, Machined plastic (delrin)



CPAS-H

Folding bracket, For heavy loads



CHN\_CHNSS

Straight long link stainless steel chain, Stainless steel

## Complementary products



CAP821

Slat top chain acetal, Large range 821



CAP805

Slat top chain stainless steel, Large range 805