



Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

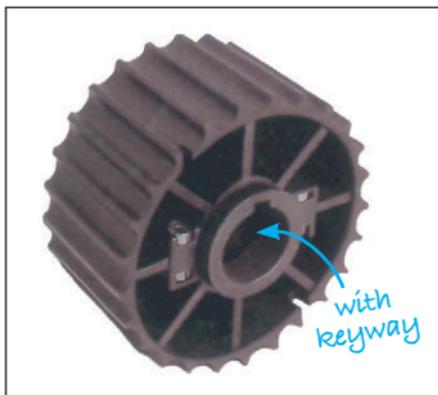

Two part design

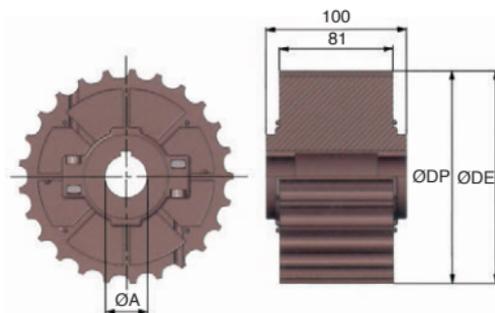

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT821-25-30	25	153	153,2	30	0,9	70,12 €
PT821-25-35	25	153	153,2	35	0,9	70,12 €
PT821-25-40	25	153	153,2	40	0,9	70,12 €
PT821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Our other products



AT10-32ECO

AT type timing pulley,
Economy range -
AT10 aluminium



CLAT

Clamping lever
Hygienic Usit® -
male, Stainless steel



BAC105

Storage bin, 8mm



PO

Pull handle - Multi-
sector, Tapped
recessed insert



GGB

Female wing knob,
Fully threaded



PNA

PERIFLEX® elastic
coupling, Complete
coupling



MHSC

Single-disc flexible
coupling, Single disk



PX_PO

Carrying handle, back-
plated



G4

Steel spur gear, Steel
20NCD2



GARQT

Quarter turn lock pin
for clamping, Quarter
turn



DOMI80

Accessories, Plate



ACLBMC

Detector support for
aluminium profile,
Sensor holder

Complementary products



CAP821

Slat top chain acetal,
Large range 821



CAP805

Slat top chain
stainless steel, Large
range 805