



# Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


## Advantage

- Two part design facilitates easy assembly

Easy assembly

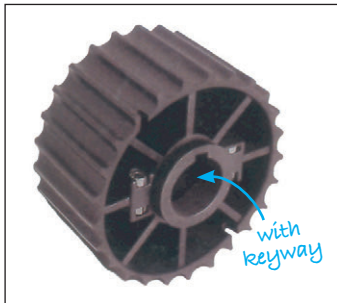

Two part design

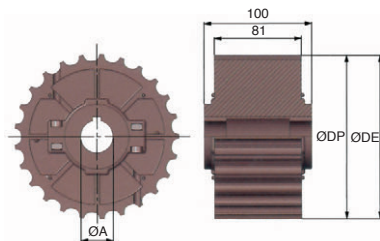

## DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT821-25-30	25	153	153,2	30	0,9	70,12 €
PT821-25-35	25	153	153,2	35	0,9	70,12 €
PT821-25-40	25	153	153,2	40	0,9	70,12 €
PT821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

## Our other products



KKSS

Rounded end feather key, Stainless steel



BDP1R

Adjustable support arm, Single clamp



NTMdl

Set screw delrin tip, Delrin-point



UFX

Uneflex® elastic coupling, range



BG

Oldham coupling, With set screw



HTD8M\_20

HTD Heavy duty timing pulley, HTD8 Steel



PRF\_PF

Anchoring bracket for aluminium profile, Anchor



CHINV

Invisible hinge, Invisible - 90° opening



PGMT

Pull handle, Stainless steel



G01

Single universal joint, Normal duty



NCT\_AT

Variable angle connector, Variable



SCE

U-shaped cable clamp, Steel

## Complementary products



CAP821

Slat top chain acetal, Large range 821



CAP805

Slat top chain stainless steel, Large range 805