



Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

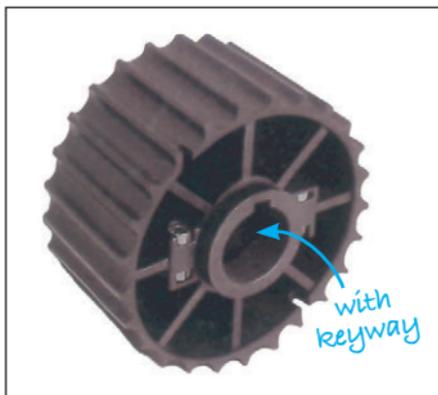

Two part design

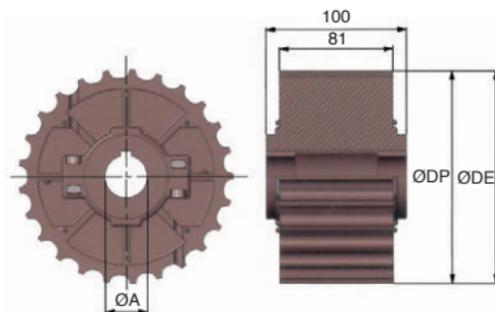

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT821-25-30	25	153	153,2	30	0,9	70,12 €
PT821-25-35	25	153	153,2	35	0,9	70,12 €
PT821-25-40	25	153	153,2	40	0,9	70,12 €
PT821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Our other products



RTE

Rotex®, jaw coupling, cast iron



BOXKU

Boxed set of half round (Woodruff) keys NFE22179, Boxed set of half ...



HFL

One way needle bearing, Needle bearing




PVL

Small lobed handle, Polyamide



PSPT

Flexible tube handle, Aluminium

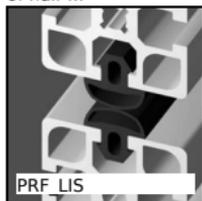

PRF LIS

Door seal for aluminium profile, Black NBR



ASM

Cylindrical polymer bush, Food grade polymer



HTD5M_15

HTD Heavy duty timing pulley, HTD5 Aluminium



SUP

Self-centering clamping hub steel, Steel



COA-COG

Surface mounting plate, Surface



CHM110

Worm and wheel gear reducer, up to 980



P40

Worm and wheel gear reducer, up to 18 Nm

Complementary products



CAP821

Slat top chain acetal, Large range 821



CAP805

Slat top chain stainless steel, Large range 805