



Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

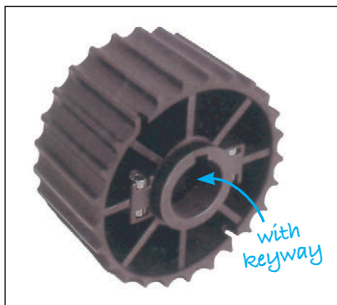

Two part design

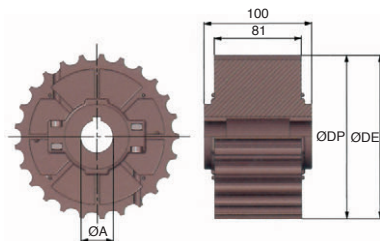

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT821-25-30	25	153	153,2	30	0,9	70,12 €
PT821-25-35	25	153	153,2	35	0,9	70,12 €
PT821-25-40	25	153	153,2	40	0,9	70,12 €
PT821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Our other products



ERF

Quick fitting threaded cable terminal, Cable terminal with threaded ...



BPHT

Ball transfer unit bolt fitting, Heavy



CNA-CNG

Right angled mounting plate, Right angled mounting plate for clevis



TBD

Manual leadscrew table with opposing threads, 40kg



PLM-C

Flat gripping magnet, Flat holding magnet



PSEC

Security pull handle, Thermoplastic



GG1

Ground spur gear, Heat treated steel



PHTss

Pull handle, Up to 250 °C



VRSF

Male swivelling lifting ring, Male swivelling



BABreglable

Adjustable ball pin hardened stainless



BLHM50

Right angled gearbox, double output shafts,



EFSM

Igubal® flange bearing, Polymer

Complementary products



CAP821

Slat top chain acetal, Large range 821



CAP805

Slat top chain stainless steel, Large range 805