

Drive sprocket for plate chain

PT880

For chain range 880 TAB

- For driving CAP880T chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

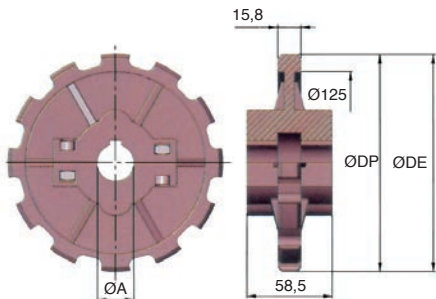

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT880-12-25	12	147,2	147,21	25	0,39	31,60 €
PT880-12-30	12	147,2	147,21	30	0,39	31,60 €
PT880-12-35	12	147,2	147,21	35	0,39	31,60 €
PT880-12-40	12	147,2	147,21	40	0,39	31,60 €

Dimensions in mm

Our other products



PT821
Drive sprocket for slat top chain, Ranges 821 and 805



UTKpwr
Utilitak® V rail, V rail



CHA1056-UPA
Molded polyamide face-mounted hinge, Black polyamide



PTAF100-PAMF100
Articulated fixable foot with pressed base Ø100, Ø 100



TCXR
Automatic chain tensioner, With steel sprocket



CHN_CHNSS
Straight long link stainless steel chain, Stainless steel



STRIP
Sealing brush strip, 1m length



BAP25
Plastic clamping collar, Ø25 - Ø40



BLH70
Right angled gearbox, from 26 to 128 Nm



CHALss
Piano hinge, Stainless steel



H0
Crossed helical gear crossed axis at 90°, Steel 20NCD2



UTKswc
Utilitak® 3 wheels carriage, Series V precision steel wheel

Complementary products



CAP880
Side flexing slim slat top chain acetal, Narrow range 880



CHM30-MOT
Asynchronous AC motorgearboxes 0.09 to 0.22kW, 0.09 to 0.22kW



CHMX_CHMDX
Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearboxes...