

Drive sprocket for plate chain

PT880

For chain range 880 TAB

- For driving CAP880T chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

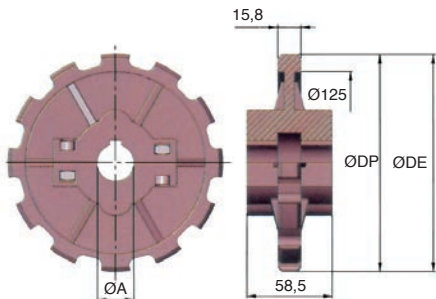

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT880-12-25	12	147,2	147,21	25	0,39	31,60 €
PT880-12-30	12	147,2	147,21	30	0,39	31,60 €
PT880-12-35	12	147,2	147,21	35	0,39	31,60 €
PT880-12-40	12	147,2	147,21	40	0,39	31,60 €

Dimensions in mm

Our other products



CHAC4040SS

Square hinge with riveted pin, drilled, Square with riveted pin, dri...



PAMF120

Articulated fixable foot, pressed bolt-down base Ø 120, Ø 120




DOMI30

Domino 30 adjustable slide, Slide DOMILINE 30



R203

 Die spring ISO10243, Light



B

Steel bevel gear, 1:1



CHMR63

Worm and wheel gear reducer, up to 196 Nm



APB_T

Adjusting rod for clamp - Female, Bored



RCC_RCX

Spherical tilt washer - DIN6319, convex



PLM-C

Cylindrical holding magnets, Cylindrical holding magnet



NCT

Square tube connector, Fixed angle



PW_PWG25

Worm - precision range, Steel



CHINV

Invisible hinge, Invisible - Opening up to 90°

Complementary products



CAP880

Side flexing slim slat top chain acetal, Narrow range 880



CHM30-MOT

Asynchronous AC motorgearboxes 0.09 to 0.22kW, 0.09 to 0.22kW



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearboxe...