

# Drive sprocket for plate chain

## PT880

## For chain range 880 TAB

- For driving CAP880T chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

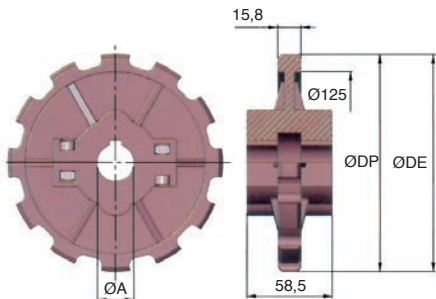

### DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT880-12-25	12	147,2	147,21	25	0,39	31,60 €
PT880-12-30	12	147,2	147,21	30	0,39	31,60 €
PT880-12-35	12	147,2	147,21	35	0,39	31,60 €
PT880-12-40	12	147,2	147,21	40	0,39	31,60 €

Dimensions in mm

## Our other products



ACLRP

Wheel for aluminium profile, Integrated bearing



UCF

Cast iron flange bearing unit, Cast iron



QNUP

Single row cylindrical roller bearing, 1 fixed inner flange and 1 fr...



IBJ

180° ball and socket joints, Steel



WW16

Drylin® W slide, slide assembly



ES

Bipod support base, Plastic



WS16

Drylin® W rail, Rail



LINK64

Synchronous AC Motor and-gearbox , from 1.3 to 6Nm



BCM\_TP

Modular cylindrical brush, Tampico



 
MDB\_MTB

Moulded plastic bevel gear (nylon), 3:1



MCL

Cylindrical threaded sleeve, Cylindrical -



G1

Steel spur gear, Steel 20NCD2

## Complementary products



CAP880

Side flexing slim slat top chain acetal, Narrow range 880



CHM30-MOT

Asynchronous AC motorgearboxes 0.09 to 0.22kW, 0.09 to 0.22kW



CHMX\_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbo...