

Drive sprocket for plate chain

PT880

For chain range 880 TAB

- For driving CAP880T chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

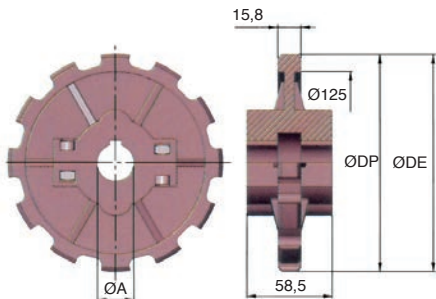

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT880-12-25	12	147,2	147,21	25	0,39	31,60 €
PT880-12-30	12	147,2	147,21	30	0,39	31,60 €
PT880-12-35	12	147,2	147,21	35	0,39	31,60 €
PT880-12-40	12	147,2	147,21	40	0,39	31,60 €

Dimensions in mm

Our other products



TIF

Threaded rod -
DIN975, Stainless
steel A2



LVTMFC

Device for controlling
limit switches, For
mini-actuator LVT



GAC

Lock for latch clamp,
Strike plate



DB

Steel bevel gear, 2:1



RDERSS

Stainless steel manual
rigging screw,
Stainless steel -
manual



BOX-TOR-C

Box set of Nitrile O-
rings in nitrile, 3.00 x
1.50mm to 30.20 x
3.00



CHAEss

Decorative hinge,
Stainless steel



SEV

Vertical stirrup toggle
clamp, Vertical Latch
Clamp - steel



 
LWL

Linear ball slide -
Stainless steel balls,
Chariot - from 514 N



LVT

Miniature motorised
actuator 1A, 1 ampere



IN2

Internal gear,
Machined plastic
(delrin)



GP75

Spring loaded toggle
latch, Standard
(GP75)

Complementary products



CAP880

Side flexing slim slat
top chain acetal,
Narrow range 880



CHM30-MOT

Asynchronous AC
motorgearboxes 0.09
to 0.22kW, 0.09 to
0.22kW



CHMX_CHMDX

Shaft for worm and
wheel reducer CHMR
and CHM, CHMR and
CHM gearboxe...