

Drive sprocket for plate chain

PT882

For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

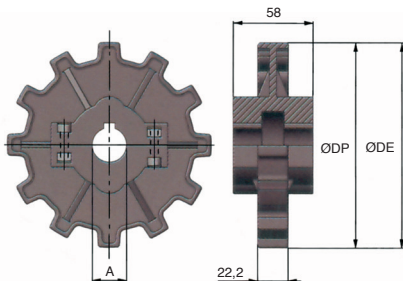

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT882-12-25	12	148,5	147,2	25	0,38	29,36 €
PT882-12-30	12	148,5	147,2	30	0,38	29,36 €
PT882-12-35	12	148,5	147,2	35	0,38	29,36 €
PT882-12-40	12	148,5	147,2	40	0,38	29,36 €
PT882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Our other products



Chain sprocket-
stainless steel, 4mm



Nut for aluminium
profile, Steel square
nut with tab



Cylindrical sintered
bronze bush, Self-
lubricating sintered
bronze



Indexing plunger,
steel class 5.8



Accessories, Plate



Parallel axis helical
gear, Machined plastic
(delrin)



Telescopic drawer,



Spur gear - precision
range, Case hardened
steel 20NCD2



Narrow spur rack,
Stainless steel



Male wing knob,
Technopolymer with



Mounting feet with
integrated castors,



Chain link, Stainless
steel

Complementary products