

Drive sprocket for plate chain

PT882

For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

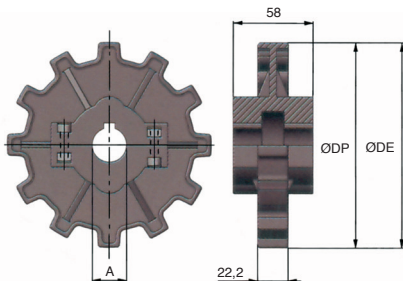

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty. | 1+ | 5+ | 10+ |
| Disc. | List | -5% | On request |

| Part number | No. of teeth | ØDE | ØDP | Bore ØA | Weight (kg) | Price each 1 to 4 |
|-------------|--------------|-------|-------|---------|-------------|-------------------|
| PT882-12-25 | 12 | 148,5 | 147,2 | 25 | 0,38 | 29,36 € |
| PT882-12-30 | 12 | 148,5 | 147,2 | 30 | 0,38 | 29,36 € |
| PT882-12-35 | 12 | 148,5 | 147,2 | 35 | 0,38 | 29,36 € |
| PT882-12-40 | 12 | 148,5 | 147,2 | 40 | 0,38 | 29,36 € |
| PT882-12-45 | 12 | 148,5 | 147,2 | 45 | 0,38 | 29,36 € |

Dimensions in mm

Our other products



HRV

V- rail guidance
Simple Select®
system, Rail with
carriage



NCT

Square tube
connector, Fixed
angle




PM2

Worm and wheel set,
Bronze



UTKswc

Utilitrak® 3 wheels
carriage, Series V
precision steel wheel

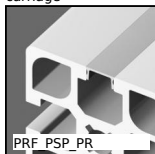

PRF PSP_PR

Dual purpose strip
and cover for
aluminium profile,
Inserts into slot



LVT

Miniature motorised
actuator 1A, 1 ampere



EX

Optional shaft for E-
type gear reducers, E
Gearboxes double
sided ou...



BCM_T

Driving collar, Driving
collar



S4

Chain sprocket-
stainless steel, 4mm



RPCplss

Fixed castor with
plate, Stainless steel -
Polyamide



RJA11_27

Sealing strip, Not
clipping



VAB

Flanged nut for ball
screw, For VAB
ballscrew

Complementary products