

# Drive sprocket for plate chain

## PT882

## For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

**Easy assembly**



Two part design

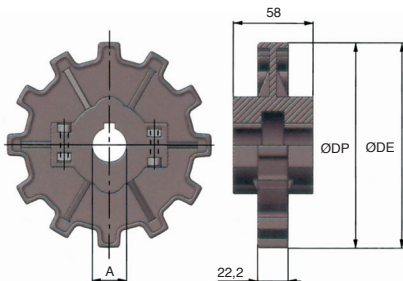

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT882-12-25	12	148,5	147,2	25	0,38	29,36 €
PT882-12-30	12	148,5	147,2	30	0,38	29,36 €
PT882-12-35	12	148,5	147,2	35	0,38	29,36 €
PT882-12-40	12	148,5	147,2	40	0,38	29,36 €
PT882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

## Our other products



CHINV2

Invisible hinge,  
Invisible - Opening up to 125°



PT881

Drive sprocket for slat  
top chain, Range 881



SC2

2 part rigid shaft  
clamp, Clamping jaw



LVT

Miniature motorised  
actuator 1A, 1 amper



MLY\_SS

Stainless steel bow  
shackle with eye bolt,  
Stainless steel



SLB

Indexing plunger,  
stainless steel



CHAFR-MINI

Miniature friction  
hinge, Friction



T10\_21\_AL

T type timing pulley,  
Economy range - T10  
aluminium




BLH40

Right angled gearbox,  
from 3 to 10.30 Nm



M1

 Worm and wheel set,  
Bronze



TIFbout

Threaded stud -  
DIN976A, Steel



APBC

Circular rod, Round  
rod

## Complementary products