

Drive sprocket for plate chain

PT882

For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

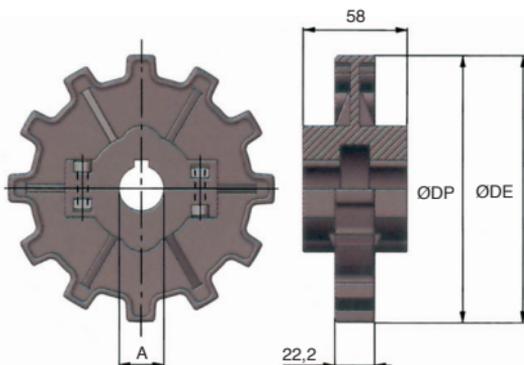

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT882-12-25	12	148,5	147,2	25	0,38	29,36 €
PT882-12-30	12	148,5	147,2	30	0,38	29,36 €
PT882-12-35	12	148,5	147,2	35	0,38	29,36 €
PT882-12-40	12	148,5	147,2	40	0,38	29,36 €
PT882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Our other products



BIMSS

Indexing plunger mini,
miniature - Stainless
steel



CMM

Male rod ends DIN
ISO12240-4, Steel /
bronze



DOMI50

Accessories, Plate



BABS303

303 Stainless steel
compact ball pin,
Stainless steel 303



ACL-APB

Closing system for
aluminium profile,
Magnetic door stop



DOMI50

Domino 50 adjustable
slide, Slide DOMILINE
50 with counter and
handw...



PCS62K

Chain sprocket with
hardened teeth,
15.875mm (DIN10B-1)



PLM-20SC

Cylindrical magnet,
Cylindrical magnet



WS16

Drylin® W rail, Rail



TBEBASE10

Economic mini-table
with trapezoidal
leadscrew, Economy



ACM_DZ

Clip for bonnet
fastener, Clip



H1

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2

Complementary products