

# Drive sprocket for plate chain



## PT882

## For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,  
please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

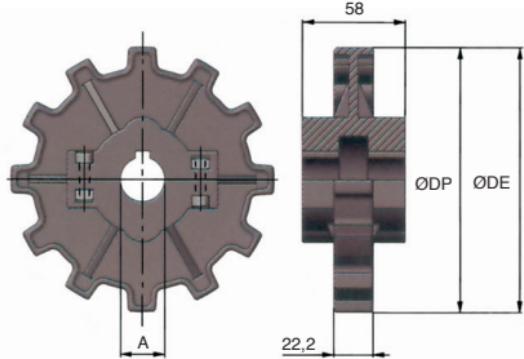

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT882-12-25	12	148,5	147,2	25	0,38	29,36 €
PT882-12-30	12	148,5	147,2	30	0,38	29,36 €
PT882-12-35	12	148,5	147,2	35	0,38	29,36 €
PT882-12-40	12	148,5	147,2	40	0,38	29,36 €
PT882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

## Our other products



ASL  
45° Hoist ring for welding, for 45° lifts - for welding



UCFL\_PBT  
Stainless steel/Polymer flanged bearing, Polymer and stainless steel



MCLred  
Reducing sleeve female/female, Cylindrical - stainless steel



WSSss  
Symmetrical S shaped hook stainless steel, Stainless steel



CHAE3030PA  
Square decorative screwed hinges, Polyamide



PRF\_PF  
Anchoring bracket for aluminium profile, Anchor



PAS  
Pull handle, Reinforced PA thermoplastic



BPHRF  
Ball transfer unit housed spring loaded, High



TM\_CTM\_CTF  
Suction cup threaded insert, Insert for suction cup - Tread



RPP  
Connecting plate for RPP type timing belts, RPP14



RBNtc  
Swivel castor with central hole, Steel - rubber - with double



NSO  
Housing for open linear bearing, Opened - long

## Complementary products