

Drive sprocket for plate chain

PT882

For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

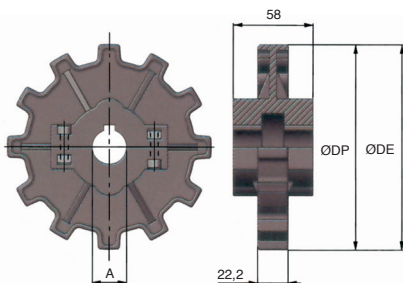

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT882-12-25	12	148,5	147,2	25	0,38	29,36 €
PT882-12-30	12	148,5	147,2	30	0,38	29,36 €
PT882-12-35	12	148,5	147,2	35	0,38	29,36 €
PT882-12-40	12	148,5	147,2	40	0,38	29,36 €
PT882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Our other products



DB

Steel bevel gear, 2:1



AT5courroie

AT type timing belt,
AT5 Steel cored
polyurethane



MEB

Moulded plastic bevel
gear (nylon), 1:1



KBS_UU

Stainless steel closed
precision linear
bearing, Precision -
stainle...



CHA_GC_14SS

Stainless steel garnet
hinge, To screw



MAX22

Motor-gearbox 12V
and 24V DC, from
0,07 to 0,2Nm



LBE

Miniature closed
linear bearing,
Miniature



CNA-CNG

Right angled
mounting plate, Right
angled mounting
plate for ball jo...



DOG319

Motor-gearbox 12V
and 24V DC, from 4 to
20 Nm



T5-10ECO

T type timing pulley,
Economy range - T5



CLASS

Stainless steel
indexing handle -



PRF4532

Standard aluminium
profile, 45 x 32 mm

Complementary products