

# Drive sprocket for plate chain

## PT882

## For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

**Easy assembly**



Two part design

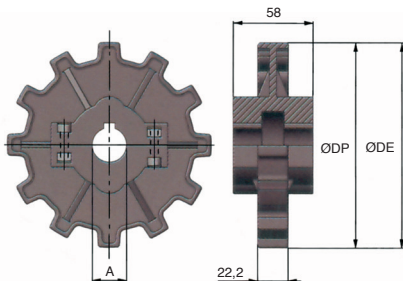


### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT882-12-25	12	148,5	147,2	25	0,38	29,36 €
PT882-12-30	12	148,5	147,2	30	0,38	29,36 €
PT882-12-35	12	148,5	147,2	35	0,38	29,36 €
PT882-12-40	12	148,5	147,2	40	0,38	29,36 €
PT882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

## Our other products

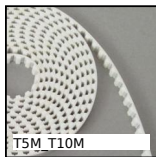

T type timing belt per metre, T5 Steel cored polyurethane



Ball transfer unit bolt fitting, Heavy



Connection for threaded actuator rod, Connection for threaded actuat...



Spur gear - precision range, Stainless steel 303



Accessory for adjustment slide-system, 20



Self locking counter nut, For axial locking



Right angled gearbox, bored shafts, up to 70 Nm



End cap for round tube, Standard



T type timing belt, T10 Steel cored



Spur gear coaxial gearbox, from 32 to



Worm and wheel gear reducer, from 2.20 to



Right angled gearbox, from 11.50 to 30 Nm

## Complementary products