

# Articulated levelling foot, pressed base Ø100 **Ste** **Sta**

## PTA100 PTA100ss

Accepts loads up to 15.000N

- Articulated foot
- Up to +/- 10° from vertical
- Materials:


### Steel version:

Base: Galvanised sheet steel C40  
Shaft: Galvanised steel (nut not supplied)  
Sole: Vulcanised NBR rubber, hardness 80° Shore

### Stainless steel version:

Base: Stainless steel sheet 304  
Shaft: Stainless steel plate 304 (nut not supplied)  
Sole: Vulcanised NBR rubber, hardness 80° Shore

*Stainless steel version, sanded finish*

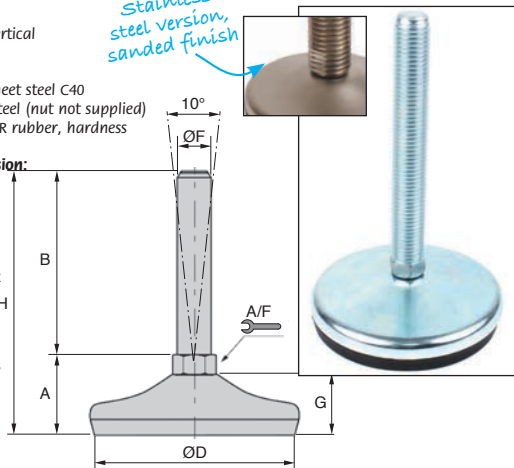

### Advantages

- Excellent Quality/Price ratio

### DISCOUNTS

Qty	1+	15+	20+	25+	40+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	Thread ØF	B	A	A/F	G	H	Load static (N)	Stock*	Price each 1 to 14
<b>Steel foot</b>										
PTA100-16-100	100	M16	100	38,0	16	28	137,5	15000	✓	25,53 €
PTA100-16-150	100	M16	150	38,0	16	28	187,5	15000	✓	28,05 €
PTA100-16-200	100	M16	200	38,0	16	28	237,5	15000	✓	28,98 €
PTA100-20-100	100	M20	100	39,0	20	28	138,5	15000	✓	26,76 €
PTA100-20-150	100	M20	150	39,0	20	28	188,5	15000	✓	29,72 €
PTA100-20-200	100	M20	200	39,0	20	28	238,5	15000	-	32,67 €
PTA100-24-100	100	M24	100	39,0	24	28	138,5	15000	-	31,63 €
PTA100-24-150	100	M24	150	39,0	24	28	188,5	15000	-	34,69 €
<b>Stainless steel foot</b>										
PTA100-16-100/SS	100	M16	100	39,5	13	30	139,5	15000	✓	49,66 €
PTA100-16-150/SS	100	M16	150	39,5	13	30	189,5	15000	✓	51,42 €
PTA100-16-200/SS	100	M16	200	39,5	13	30	239,5	15000	-	55,56 €
PTA100-20-100/SS	100	M20	100	43,0	17	30	143,0	15000	-	53,21 €
PTA100-20-150/SS	100	M20	150	43,0	17	30	193,0	15000	✓	56,75 €
PTA100-20-200/SS	100	M20	200	43,0	17	30	243,0	15000	-	60,88 €
PTA100-24-100/SS	100	M24	100	44,0	20	30	144,0	15000	-	57,33 €
PTA100-24-150/SS	100	M24	150	44,0	20	30	194,0	15000	-	59,12 €


\*Depending on availability - Dimensions in mm

## Our other products



PTA50ssEB

Articulated foot with sheet metal base  
Ø50, Articulated foot

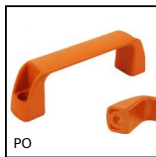

PO

Pull handle - Multi-sector, Smooth hole




H0

Crossed helical gear  
crossed axis at 90°,  
Steel 20NCD2



PV2R

 Adjustable suction-cup support,  
Increased grip



LAT1

1A motorised linear actuator, 1 ampere



MLY

Bow shackle with eye bolt, Steel



BLHB20

Right angled gearbox,  
bored shafts, up to  
1.77 Nm



PRFRTR

Cross connector for aluminium profile,  
Cross connector



CHTRB

Single and dual output gearboxes, Up to 4,7 Nm



TCC\_SS

Stainless steel rigging screw (hook/hook),  
Stainless steel



PR820

Idle sprocket for slat top chain, Rangs 820 and 815



BHC

Socket head button screw, Stainless steel A2

## Complementary products



PTA150

Articulated levelling foot, pressed base  
Ø150, Ø 150