

Articulated foot with sheet metal base Ø100

PTA100SS/EB

Max load: 15,000N
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

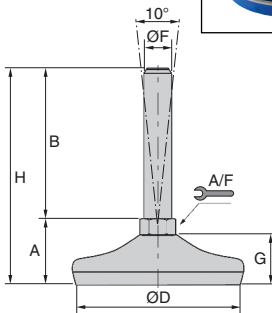

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA100-16-100/SS/EB	100	M16	100	39.5	13	30	139.5	15000	45,66€
PTA100-16-150/SS/EB	100	M16	150	39.5	13	30	189.5	15000	47,28€
PTA100-16-200/SS/EB	100	M16	200	39.5	13	30	239.5	15000	50,98€
PTA100-20-100/SS/EB	100	M20	100	43.0	17	30	143.0	15000	48,84€
PTA100-20-150/SS/EB	100	M20	150	43.0	17	30	193.0	15000	51,99€
PTA100-20-200/SS/EB	100	M20	200	43.0	17	30	243.0	15000	55,69€
PTA100-24-100/SS/EB	100	M24	100	44.0	20	30	144.0	15000	52,54€
PTA100-24-150/SS/EB	100	M24	150	44.0	20	30	194.0	15000	54,13€

* Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



BOX-TOR-D

Box set of Nitrile O-rings in nitrile, 18.00 x 2.00mm to 50.00 x 5.00



WING

Manually tightened wing nut, Stainless steel DIN 314/315



GAL_25

Ø25 conveyor roller, Without ball bearing



GB-RA

Brass spur gear, Brass CuZn39Pb3



SHS

Shoulder screw stainless steel 303, Stainless steel 303



PW_PWG2

Wheel - precision range, Bronze



PR85

Articulated foot Ø83, Ø 83



MSP3815

Masterplate® glueable insert rectangular, rectangular with



PSPD40

Flexible tube handle, Black PVC



PT881

Drive sprocket for slat top chain, Range 881



FBL4004_K32

Brush strip per metre, Black striated polypropylene (PP)



T10courroie

T type timing belt, T10 Steel cored polyurethane

Complementary products



PTA50ssEB

Articulated foot with sheet metal base Ø50, Articulated foot



PTA80ssEB

Articulated foot with sheet metal base Ø80, Articulated foot



PAMF80EB

Articulated foot with sheet metal base Ø80, Articulated foot



PAMF100EB

Articulated foot with sheet metal base Ø100, Articulated foot