

# Articulated foot with sheet metal base Ø100

## PTA100SS/EB

Max load: 15,000N  
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

### Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

### Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

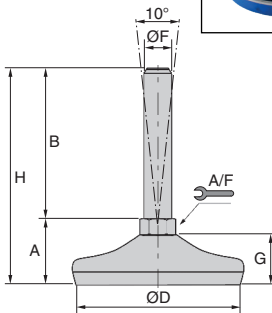

### DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA100-16-100/SS/EB	100	M16	100	39.5	13	30	139.5	15000	45,66€
PTA100-16-150/SS/EB	100	M16	150	39.5	13	30	189.5	15000	47,28€
PTA100-16-200/SS/EB	100	M16	200	39.5	13	30	239.5	15000	50,98€
PTA100-20-100/SS/EB	100	M20	100	43.0	17	30	143.0	15000	48,84€
PTA100-20-150/SS/EB	100	M20	150	43.0	17	30	193.0	15000	51,99€
PTA100-20-200/SS/EB	100	M20	200	43.0	17	30	243.0	15000	55,69€
PTA100-24-100/SS/EB	100	M24	100	44.0	20	30	144.0	15000	52,54€
PTA100-24-150/SS/EB	100	M24	150	44.0	20	30	194.0	15000	54,13€

\* Depending on availability - Dimensions in mm

**HPC**

WEB  
04/2020

www.hpceurope.com


Tél: 0 825 88 5000 Service 0,15€/min + prix appel

## Our other products



PRF4590\_E

Bracket for aluminium profile, PRF4590

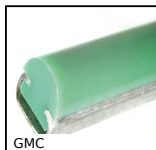

GMC

Flat profile - Round guide, Flat profile - round guide



BABS

630 Stainless steel compact ball pin, Hardened stainless steel



CHM90

Worm and wheel gear reducer, up to 540 Nm




SH3

Parallel axis helical gear, Steel 20NCD2



YG1

HEAVY DUTY spur gear, Steel 35NCD6

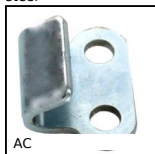

AC

Strike for toggle latch, 18mm



BPLE

Ball transfer unit push fit, Light



GARBAB

Lock pin for clamping, Ball lock pin



UGH16

H Type Guide units, For Ø12 and Ø16 actuators



COA-COG

Surface mounting plate, Surface mounting plate for



NT121

Spur gear coaxial gearbox, from 20 to 68 Nm - In-line

## Complementary products



PTA50ssEB

Articulated foot with sheet metal base  
Ø50, Articulated foot



PTA80ssEB

Articulated foot with sheet metal base  
Ø80, Articulated foot



PAMF80EB

Articulated foot with sheet metal base  
Ø80, Articulated foot



PAMF100EB

Articulated foot with sheet metal base  
Ø100, Articulated foot