

# Articulated foot with sheet metal base Ø100

## PTA100SS/EB

Max load: 15,000N  
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

### Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

### Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

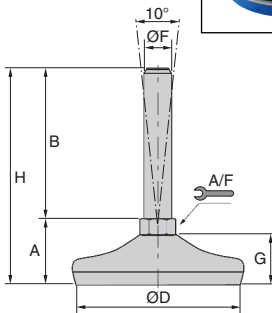

### DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA100-16-100/SS/EB	100	M16	100	39.5	13	30	139.5	15000	45,66€
PTA100-16-150/SS/EB	100	M16	150	39.5	13	30	189.5	15000	47,28€
PTA100-16-200/SS/EB	100	M16	200	39.5	13	30	239.5	15000	50,98€
PTA100-20-100/SS/EB	100	M20	100	43.0	17	30	143.0	15000	48,84€
PTA100-20-150/SS/EB	100	M20	150	43.0	17	30	193.0	15000	51,99€
PTA100-20-200/SS/EB	100	M20	200	43.0	17	30	243.0	15000	55,69€
PTA100-24-100/SS/EB	100	M24	100	44.0	20	30	144.0	15000	52,54€
PTA100-24-150/SS/EB	100	M24	150	44.0	20	30	194.0	15000	54,13€

\* Depending on availability - Dimensions in mm

**HPC**

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

 
## Our other products



KB\_WW  
Closed linear precision bearing, Economy range




CHTRP  
Single and dual output gearboxes, Up to 28,8 Nm




CHB  
Worm and wheel gear reducer, up to 22 Nm



 BABPass  
Hardened stainless steel ball pin with ring, With grip ring



PX\_PO  
Carrying handle, back-plated

 

RPP  
Connecting plate for RPP type timing belts, RPPB



BOX-TOR-D  
Box set of Nitrile O-rings in nitrile, 18.00 x 2.00mm to 50.00 x 5.00



ACA  
Steel splined shaft, Steel



RJA00\_28  
Sealing strip, Clipping



ADL\_M  
Male eye bolt conforms to DIN580,



SLH  
Horizontal toggle clamp, Horizontal



EMAS  
Antistatic knurled nut, Antistatic

## Complementary products



PTA50ssEB  
Articulated foot with sheet metal base Ø50, Articulated foot



PTA80ssEB  
Articulated foot with sheet metal base Ø80, Articulated foot



PAMF80EB  
Articulated foot with sheet metal base Ø80, Articulated foot



PAMF100EB  
Articulated foot with sheet metal base Ø100, Articulated foot