

Articulated foot with sheet metal base Ø100

PTA100SS/EB

Max load: 15,000N
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

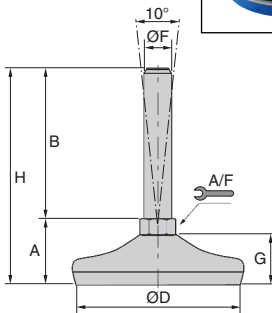

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA100-16-100/SS/EB	100	M16	100	39.5	13	30	139.5	15000	45,66€
PTA100-16-150/SS/EB	100	M16	150	39.5	13	30	189.5	15000	47,28€
PTA100-16-200/SS/EB	100	M16	200	39.5	13	30	239.5	15000	50,98€
PTA100-20-100/SS/EB	100	M20	100	43.0	17	30	143.0	15000	48,84€
PTA100-20-150/SS/EB	100	M20	150	43.0	17	30	193.0	15000	51,99€
PTA100-20-200/SS/EB	100	M20	200	43.0	17	30	243.0	15000	55,69€
PTA100-24-100/SS/EB	100	M24	100	44.0	20	30	144.0	15000	52,54€
PTA100-24-150/SS/EB	100	M24	150	44.0	20	30	194.0	15000	54,13€

* Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



AC
Strike for toggle latch,
15mm



M1
Worm and wheel set,
Hardened steel



PSG155
Spur gear - precision
range, Stainless steel
316



HRV
V-rail guidance
Simple Select®
system, Rail with
carriage




BOX-TOR-A
Box set of Nitrile O-
rings in nitrile, 2.90 x
1.78mm to 28.17 x
3.53



DBL880
Idler for slat top
chain, Ranges 880
and 881



 SA_SAKH
Housing for linear
bearing, Closed - light
load



AC
Strike for toggle latch,
15mm



PR881
Idler sprocket for slat
top chain, Range 881



SLB
Indexing plunger,
stainless steel



DOM180
Accessories, Plate



PF40
Worm and wheel gear
reducer, up to 18 Nm

Complementary products



PTA50ssEB
Articulated foot with
sheet metal base
Ø50, Articulated foot



PTA80ssEB
Articulated foot with
sheet metal base
Ø80, Articulated foot



PAMF80EB
Articulated foot with
sheet metal base
Ø80, Articulated foot



PAMF100EB
Articulated foot with
sheet metal base
Ø100, Articulated foot