

Articulated foot with sheet metal base Ø100

PTA100SS/EB

Max load: 15,000N
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

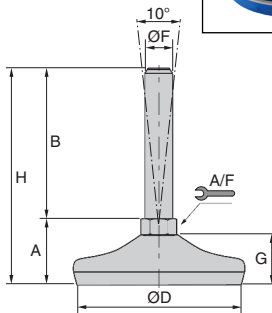

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA100-16-100/SS/EB	100	M16	100	39.5	13	30	139.5	15000	45,66€
PTA100-16-150/SS/EB	100	M16	150	39.5	13	30	189.5	15000	47,28€
PTA100-16-200/SS/EB	100	M16	200	39.5	13	30	239.5	15000	50,98€
PTA100-20-100/SS/EB	100	M20	100	43.0	17	30	143.0	15000	48,84€
PTA100-20-150/SS/EB	100	M20	150	43.0	17	30	193.0	15000	51,99€
PTA100-20-200/SS/EB	100	M20	200	43.0	17	30	243.0	15000	55,69€
PTA100-24-100/SS/EB	100	M24	100	44.0	20	30	144.0	15000	52,54€
PTA100-24-150/SS/EB	100	M24	150	44.0	20	30	194.0	15000	54,13€

* Depending on availability - Dimensions in mm

Our other products



GE_ES_2R5

Spherical bushing,
Steel / steel with seals



BPFss

Pressed stainless
steel flange bearing,
Stainless steel



MFB_MHB

Moulded plastic bevel
gear (nylon), 4:1



BAG

Steel Clamping collar,
Steel



 
PW_PWG25

Worm - precision
range, Stainless steel



VTLF

3 lobed handle,
Polyamide - Brass



B

Steel bevel gear, 1:1



LRR-53

Spring loaded latch,
Spring return latch -
steel



 
QNU

Single row cylindrical
roller bearing, Free



PITA

Locking bolt, with T
handle



PRZ

Wear strip for slat profile to be



PITAss

Locking bolt, with T
handle

Complementary products



PTA50ssEB

Articulated foot with
sheet metal base
Ø50, Articulated foot



PTA80ssEB

Articulated foot with
sheet metal base
Ø80, Articulated foot



PAMF80EB

Articulated foot with
sheet metal base
Ø80, Articulated foot



PAMF100EB

Articulated foot with
sheet metal base
Ø100, Articulated foot