

Articulated foot with sheet metal base Ø100

PTA100SS/EB

Max load: 15,000N
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

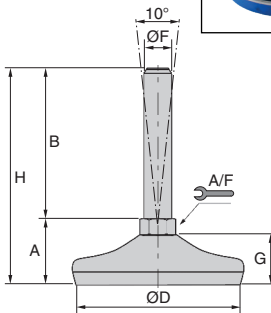

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA100-16-100/SS/EB	100	M16	100	39.5	13	30	139.5	15000	45,66€
PTA100-16-150/SS/EB	100	M16	150	39.5	13	30	189.5	15000	47,28€
PTA100-16-200/SS/EB	100	M16	200	39.5	13	30	239.5	15000	50,98€
PTA100-20-100/SS/EB	100	M20	100	43.0	17	30	143.0	15000	48,84€
PTA100-20-150/SS/EB	100	M20	150	43.0	17	30	193.0	15000	51,99€
PTA100-20-200/SS/EB	100	M20	200	43.0	17	30	243.0	15000	55,69€
PTA100-24-100/SS/EB	100	M24	100	44.0	20	30	144.0	15000	52,54€
PTA100-24-150/SS/EB	100	M24	150	44.0	20	30	194.0	15000	54,13€

* Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



RPCplss

Swivel castor with plate, Stainless steel - Polyamide



CMA

Eye bolt, Steel




PRF19_E

Bracket for aluminium profile, PRF19 to PRF45



DOMI120

 Accessories, Turntable



PM3

Worm and wheel set, Machined plastic (delrin)



M

Bellows cover, Accessory:



PRESS5HR

Manual workbench press, Force up to 500kg



G2

Steel spur gear, Steel 20NCD2



PR40

Articulated foot Ø40, Ø 40



G3

Steel spur gear, Steel 20NCD2



TMR

Rigid manual tensioner, Adjustable



PRF_PIV

Internal hinge pin for aluminium profile, Internal hinge pin

Complementary products



PTA50ssEB

Articulated foot with sheet metal base Ø50, Articulated foot



PTA80ssEB

Articulated foot with sheet metal base Ø80, Articulated foot



PAMF80EB

Articulated foot with sheet metal base Ø80, Articulated foot



PAMF100EB

Articulated foot with sheet metal base Ø100, Articulated foot