

SteSta Pressed steel articulated foot Ø150

Accepts loads up to 40,000N

PTA150
PTA150ss

- **Levelling foot**
- Brilliant finish (Sand-blasted finish for base of the stainless steel version)
- Materials:

Steel version:

Base: Chromed steel sheet C40

Rod: Chromed steel (nut not supplied)

Sole: Vulcanised rubber NBR hardness

80° Shore


Stainless steel version:

Base: 304 stainless steel, brilliant or sand-blasted finish

Rod: 304 stainless steel (nut not supplied)

Sole: Vulcanised rubber NBR hardness 80° Shore

Sand-blasted stainless-steel version

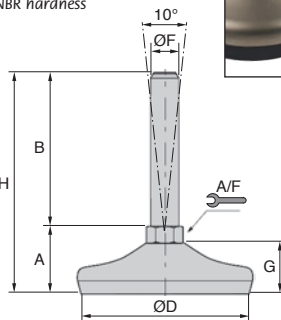

Options

- Other rod sizes are available

DISCOUNTS

Qty	1+	15+	20+	25+	40+
Disc.	List -5%	-10%	-15%		On request

Part number		ØD	ØF	B	A	A/F	G	H	Static load (N)	Price each 1 to 14
bright	sanded finish									
Steel foot										
PTA150-24-100	-	150	M24	100	44	24	35	144	40000	52,69 €
PTA150-24-150	-	150	M24	150	44	24	35	194	40000	55,61 €
PTA150-24-200	-	150	M24	200	44	24	35	244	40000	58,77 €
PTA150-24-250	-	150	M24	250	44	24	35	294	40000	61,72 €
PTA150-30-100	-	150	M30	100	44	30	35	145	40000	57,84 €
PTA150-30-150	-	150	M30	150	44	30	35	195	40000	59,65 €
PTA150-30-200	-	150	M30	200	44	30	35	245	40000	65,66 €
PTA150-30-250	-	150	M30	250	44	30	35	295	40000	73,95 €
Stainless steel foot										
PTA150-24-100/SS	PTA150-24-100/SS/SB	150	M24	100	49	20	35	149	40000	72,32 €
PTA150-24-150/SS	PTA150-24-150/SS/SB	150	M24	150	49	20	35	199	40000	76,29 €
PTA150-24-200/SS	PTA150-24-200/SS/SB	150	M24	200	49	20	35	249	40000	80,27 €
PTA150-24-250/SS	PTA150-24-250/SS/SB	150	M24	250	49	20	35	299	40000	84,26 €
PTA150-30-100/SS	PTA150-30-100/SS/SB	150	M30	100	50	26	35	150	40000	82,29 €
PTA150-30-150/SS	PTA150-30-150/SS/SB	150	M30	150	50	26	35	200	40000	88,11 €
PTA150-30-200/SS	PTA150-30-200/SS/SB	150	M30	200	50	26	35	250	40000	93,00 €
PTA150-30-250/SS	PTA150-30-250/SS/SB	150	M30	250	50	26	35	300	40000	97,86 €

All dimensions in mm

Fax **0 825 88 6000**
Service 0,15 €/min
+ prix appel

cial2@hpceurope.com

HPC SUPPLEMENT 2019

Our other products




UCFL_PBT
Flange bearing,
Polymer and stainless
steel



CHML63
Worm and wheel
gearbox, up to 138
Nm - Integrated
torque limiter



 WBGV
Lifting ring, Threaded



CRM
Rack, square section,
Nylon



NSA
Adjustable cross
clamp, Articulated



PRF_BASE
Floor anchor, Base
plate



BAC105
Storage bin, 8mm



GSI_A
Gas spring, Gas
control screw



VPRA_M
Hand wheel,
Thermosetting plastic
- galvanised steel hub



SVT5
Screwjack, with
translating screw



DB
Bevel gear - Steel
60C40, 2:1



Q6
Ball bearing, Steel

Complementary products



PTA100
Levelling foot with
solid base, Ø 150



PTA100
Articulated foot with
pressed base, Ø 150



PTA100
Articulated foot with
pressed base, Ø 100