



# Articulated foot with sheet metal base Ø40

Max load: 4000N  
Rubber sole in EPDM, blue

PTA40SS/EB

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:  
Base: shiny 304 stainless steel sheet  
Thread: 304 stainless steel, supplied without nut  
Sole: EPDM blue

## Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

## Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

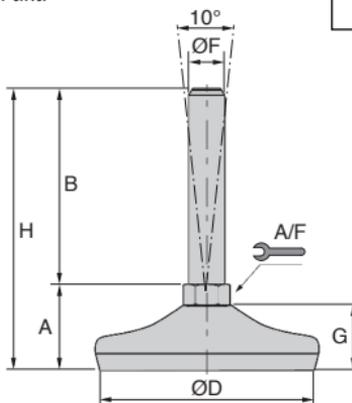

## DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price	-5%	-10%	-15%	-15%	On request

Part number	ØD	ØF	B	A	A/F	G	H	Static load (N)	Stock*	Price per unit 1 to 5
PTA40-8-25/SS/EB	40	M8	25	26	6	15	51	3000	-	13,14 €
PTA40-8-50/SS/EB	40	M8	50	26	6	15	76	3000	-	13,53 €
PTA40-8-75/SS/EB	40	M8	75	26	6	15	101	3000	-	14,01 €
PTA40-10-25/SS/EB	40	M10	25	26	8	15	51	3000	-	14,31 €
PTA40-10-50/SS/EB	40	M10	50	26	8	15	76	3000	-	14,76 €
PTA40-10-75/SS/EB	40	M10	75	26	8	15	101	3000	-	15,21 €
PTA40-10-100/SS/EB	40	M10	100	26	8	15	126	3000	-	16,08 €
PTA40-10-125/SS/EB	40	M10	125	26	8	15	151	3000	-	16,71 €

\* Depending on availability - Dimensions in mm

# Articulated foot with sheet metal base Ø50

Max load: 4000N  
Rubber sole in EPDM, blue


- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

## Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

## Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

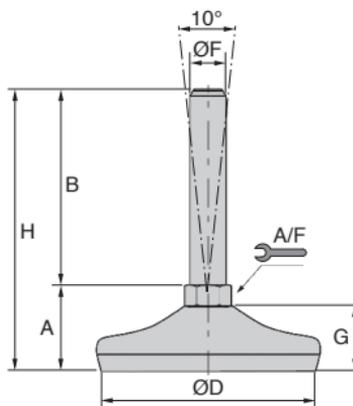

## DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA50-10-75/SS/EB	50	M10	75	29	14	19	104	4,000	18,61 €
PTA50-10-125/SS/EB	50	M10	125	29	14	19	154	4,000	21,00 €
PTA50-12-75/SS/EB	50	M12	75	29	14	19	104	4,000	18,61 €
PTA50-12-125/SS/EB	50	M12	125	29	14	19	154	4,000	21,00 €
PTA50-16-75/SS/EB	50	M16	75	34	13	19	109	4,000	21,58 €
PTA50-16-100/SS/EB	50	M16	100	34	13	19	134	4,000	22,40 €
PTA50-16-150/SS/EB	50	M16	150	34	13	19	184	4,000	24,51 €

\* Depending on availability - Dimensions in mm



# Articulated foot with sheet metal base Ø80

Max load: 10,000N  
Rubber sole in EPDM, blue

PTA80SS/EB

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

## Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

## Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

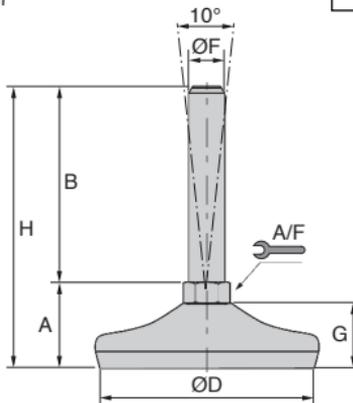

## DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA80-12-100/SS/EB	80	M12	100	35	14	25	135	10000	31,38 €
PTA80-12-150/SS/EB	80	M12	150	35	14	25	185	10000	33,65 €
PTA80-16-100/SS/EB	80	M16	100	35	13	25	135	10000	33,65 €
PTA80-16-150/SS/EB	80	M16	150	35	13	25	185	10000	35,85 €
PTA80-20-100/SS/EB	80	M20	100	38	17	25	138	10000	37,57 €
PTA80-20-150/SS/EB	80	M20	150	38	17	25	188	10000	40,32 €
PTA80-20-200/SS/EB	80	M20	200	38	17	25	238	10000	44,54 €

\* Depending on availability - Dimensions in mm

# Articulated foot with sheet metal base Ø100

## PTA100SS/EB

Max load: 15,000N  
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

### Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

### Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

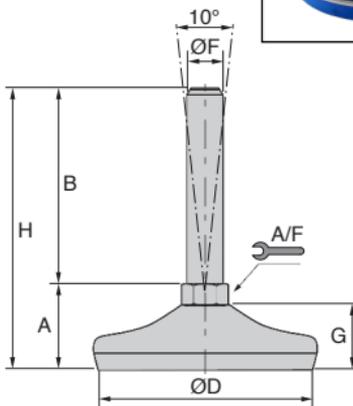

### DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA100-16-100/SS/EB	100	M16	100	39.5	13	30	139.5	15000	48,36 €
PTA100-16-150/SS/EB	100	M16	150	39.5	13	30	189.5	15000	50,09 €
PTA100-16-200/SS/EB	100	M16	200	39.5	13	30	239.5	15000	54,00 €
PTA100-20-100/SS/EB	100	M20	100	43.0	17	30	143.0	15000	51,73 €
PTA100-20-150/SS/EB	100	M20	150	43.0	17	30	193.0	15000	55,07 €
PTA100-20-200/SS/EB	100	M20	200	43.0	17	30	243.0	15000	59,00 €
PTA100-24-100/SS/EB	100	M24	100	44.0	20	30	144.0	15000	55,66 €
PTA100-24-150/SS/EB	100	M24	150	44.0	20	30	194.0	15000	57,35 €

\* Depending on availability - Dimensions in mm



# Articulated foot with sheet metal base Ø80

Max load: 10,000N

PAMF80EB

Rubber sole in EPDM, blue


- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

## Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

## Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

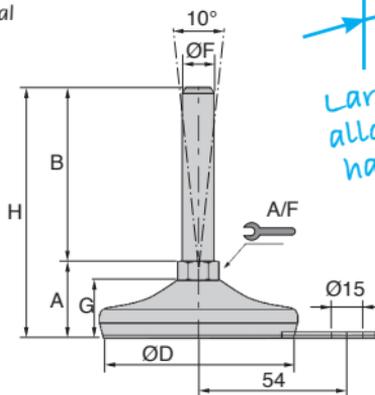

## DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PAMF80-12-100/EB	80	M12	100	35	14	25	135	10000	38,93 €
PAMF80-12-150/EB	80	M12	150	35	14	25	185	10000	41,14 €
PAMF80-16-75/EB	80	M16	75	35	13	25	110	10000	39,46 €
PAMF80-16-125/EB	80	M16	125	35	13	25	160	10000	42,27 €
PAMF80-16-175/EB	80	M16	175	35	13	25	210	10000	45,06 €
PAMF80-20-100/EB	80	M20	100	38	17	25	138	10000	45,06 €
PAMF80-20-150/EB	80	M20	150	38	17	25	188	10000	47,85 €
PAMF80-20-200/EB	80	M20	200	38	17	25	238	10000	52,03 €

\*Within the limits of available stock - Dimensions in mm

# Articulated foot with sheet metal base Ø100

## PAMF100EB

Max load: 15,000N  
Rubber sole in EPDM, blue

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:

Base: shiny 304 stainless steel sheet  
Thread: 304 stainless steel, supplied without nut  
Sole: EPDM blue

### Options

- Other thread dimensions on request
- 316 grade Stainless steel on request


### Advantages

- Hygienic special pad for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

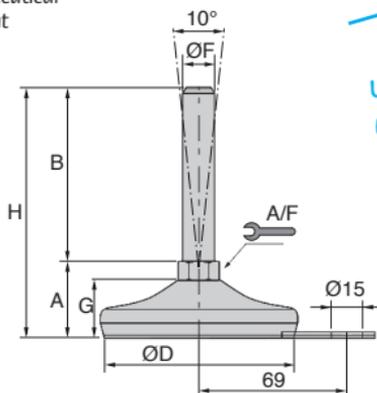

### DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price	-5%	-10%	-15%	On request	

Part N°	Threading			A	A/F	G	H	Static load(N)	Price per unit 1 to 5
	ØD	ØF	B						
PAMF100-16-100/EB	100	M16	100	39.5	13	30	139.5	15000	56,53 €
PAMF100-16-150/EB	100	M16	150	39.5	13	30	189.5	15000	58,24 €
PAMF100-16-200/EB	100	M16	200	39.5	13	30	239.5	15000	62,18 €
PAMF100-20-100/EB	100	M20	100	43.0	17	30	143.0	15000	59,90 €
PAMF100-20-150/EB	100	M20	150	43.0	17	30	193.0	15000	63,32 €
PAMF100-20-200/EB	100	M20	200	43.0	17	30	243.0	15000	67,23 €

\* Depending on availability - Dimensions in mm

## Our other products



Worm , Hardened steel



Hinge for aluminium profile, Hinge



Parallel axis helical gear, Machined plastic (delrin)



Base plate for aluminium profile, Base plate



Optional shaft for E-type gear reducers, E Gearboxes double sided ou...



Bracket for aluminium profile, PRF19 to PRF45



Short housing for open linear bearing, Opened - slim



Suction cup, 1.5 bellows, nitrile



Antistatic brush, Standard



Hinge for aluminium profile, With elongated holes



Manual locking clamp, Manual locking clamp T



Parallel axis helical gear, Machined plastic (delrin)

## Complementary products



Articulated foot with sheet metal base  
Ø50, 4 000N



Articulated foot with sheet metal base  
Ø80, 10000N



Articulated foot with sheet metal base  
Ø100, 15000N



Articulated foot with sheet metal base  
Ø80, Articulated foot