

Articulated foot with solid base Ø50 **StaSte**

PTA50 PTA50ss

Accepts loads up to 4.000N

- **Articulated foot**
- Up to +/- 10° from vertical
- **Materials:**

Steel version:

Base: Galvanised sheet steel C40
Shaft: Galvanised steel (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:


Base: Sheet stainless steel 304
Shaft: Stainless steel 304 (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version, sanded finish



Advantages

- Excellent Price-Quality ratio

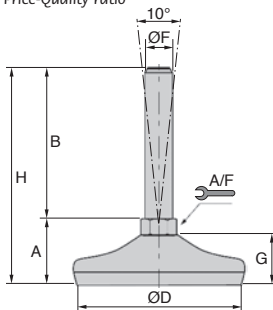


DISCOUNTS

Qty	1+	15+	20+	25+	40+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	Thread ØF	B	A	A/F	G	H	Load static (N)	Stock*	Price each 1 to 14
Steel foot										
PTA50-10-100	50	M10	100	29	14	19	129	4000	✓	14,72 €
PTA50-12-100	50	M12	100	29	14	19	129	4000	✓	14,72 €
PTA50-12-150	50	M12	150	29	14	19	179	4000	✓	15,87 €
PTA50-16-75	50	M16	75	29	16	19	104	4000	✓	15,09 €
PTA50-16-100	50	M16	100	29	16	19	129	4000	-	16,13 €
PTA50-16-150	50	M16	150	29	16	19	179	4000	-	18,28 €
Stainless steel foot										
PTA50-10-75/SS	50	M10	75	29	14	19	104	4000	✓	15,95 €
PTA50-10-125/SS	50	M10	125	29	14	19	154	4000	✓	18,14 €
PTA50-12-75/SS	50	M12	75	29	14	19	104	4000	✓	15,95 €
PTA50-12-125/SS	50	M12	125	29	14	19	154	4000	✓	18,14 €
PTA50-16-75/SS	50	M16	75	34	13	19	109	4000	✓	18,62 €
PTA50-16-100/SS	50	M16	100	34	13	19	134	4000	-	19,34 €
PTA50-16-150/SS	50	M16	150	34	13	19	184	4000	-	21,27 €

*Depending on availability - Dimensions in mm

Our other products

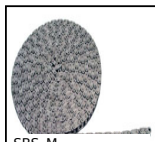

SBS_M

Single chain supplied by the metre, Stainless steel



CLB_T

Die cast zinc clamping lever - male, Zamak



S2B

Short linear bearing housing, Closed - Slim



HLC28

Right angle spiro bevel gearbox, Up to 182Nm



WINGbr

Wing screw, hand tightened DIN316, Brass DIN 316



FF40

Offset spur gear reducer, from 59 to 210 Nm



VTH

Hexagonal headed bolts, Steel class 8.8



SC2

2 part rigid shaft clamp, Clamping jaw



SCA_SS

Stainless steel flat cable clamp, Stainless



MSP23

Masterplate® glueable insert Ø23,



gt64

Rotating bent lever, Common applications



ES

Bipod support base, Plastic

Complementary products