

Articulated foot with solid base Ø50 **StaSte**

PTA50 Accepts loads up to 4.000N
PTA50ss

- **Articulated foot**
- Up to +/- 10° from vertical
- **Materials:**

Steel version:

Base: Galvanised sheet steel C40
 Shaft: Galvanised steel (nut not supplied)
 Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:


Base: Sheet stainless steel 304
 Shaft: Stainless steel 304 (nut not supplied)
 Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version, sanded finish



Advantages

- Excellent Price-Quality ratio

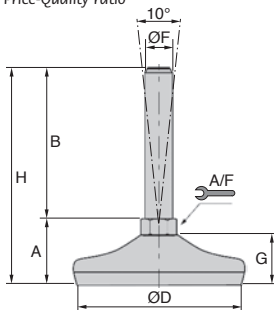

DISCOUNTS

Qty	1+	15+	20+	25+	40+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	Thread ØF	B	A	A/F	G	H	Load static (N)	Stock*	Price each 1 to 14
Steel foot										
PTA50-10-100	50	M10	100	29	14	19	129	4000	✓	14,72 €
PTA50-12-100	50	M12	100	29	14	19	129	4000	✓	14,72 €
PTA50-12-150	50	M12	150	29	14	19	179	4000	✓	15,87 €
PTA50-16-75	50	M16	75	29	16	19	104	4000	✓	15,09 €
PTA50-16-100	50	M16	100	29	16	19	129	4000	-	16,13 €
PTA50-16-150	50	M16	150	29	16	19	179	4000	-	18,28 €
Stainless steel foot										
PTA50-10-75/SS	50	M10	75	29	14	19	104	4000	✓	15,95 €
PTA50-10-125/SS	50	M10	125	29	14	19	154	4000	✓	18,14 €
PTA50-12-75/SS	50	M12	75	29	14	19	104	4000	✓	15,95 €
PTA50-12-125/SS	50	M12	125	29	14	19	154	4000	✓	18,14 €
PTA50-16-75/SS	50	M16	75	34	13	19	109	4000	✓	18,62 €
PTA50-16-100/SS	50	M16	100	34	13	19	134	4000	-	19,34 €
PTA50-16-150/SS	50	M16	150	34	13	19	184	4000	-	21,27 €

*Depending on availability - Dimensions in mm

Our other products



HTD14M_85
HTD Heavy duty timing pulley, HTD14 Steel



T2,5-BAR
T type tooth bar stock, T2.5



IBJ
180° ball and socket joints, Steel



MRS
Stainless steel metric section rack, Stainless steel



SERB
Cam latch, Cam latch




WJUM16
Drylin® W bearing block, Slide



ACL
Joints for aluminium profile, Variable angle hinge



CHA_GC_14SS
Stainless steel garnet hinge, To screw

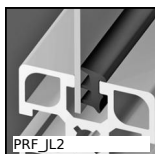

PRF_JL2
Lip seal for panel, Door seal - Ø 2mm



CHA35
Hinge for aluminium profile, Hinge



DOMI120
Accessories, Turntable



SVR30
Screwjack with travelling nut, with moving nut

Complementary products