

Articulated foot with solid base Ø50 **StaSte**

PTA50 Accepts loads up to 4.000N
PTA50ss

- **Articulated foot**
- Up to +/- 10° from vertical
- **Materials:**

Steel version:

Base: Galvanised sheet steel C40
 Shaft: Galvanised steel (nut not supplied)
 Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:


Base: Sheet stainless steel 304
 Shaft: Stainless steel 304 (nut not supplied)
 Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version, sanded finish



Advantages

- Excellent Price-Quality ratio

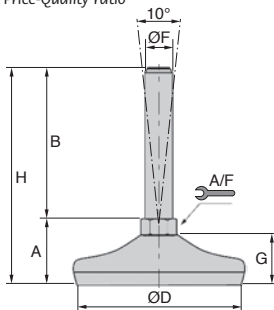

DISCOUNTS

Qty	1+	15+	20+	25+	40+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	Thread ØF	B	A	A/F	G	H	Load static (N)	Stock*	Price each 1 to 14
Steel foot										
PTA50-10-100	50	M10	100	29	14	19	129	4000	✓	14,72 €
PTA50-12-100	50	M12	100	29	14	19	129	4000	✓	14,72 €
PTA50-12-150	50	M12	150	29	14	19	179	4000	✓	15,87 €
PTA50-16-75	50	M16	75	29	16	19	104	4000	✓	15,09 €
PTA50-16-100	50	M16	100	29	16	19	129	4000	-	16,13 €
PTA50-16-150	50	M16	150	29	16	19	179	4000	-	18,28 €
Stainless steel foot										
PTA50-10-75/SS	50	M10	75	29	14	19	104	4000	✓	15,95 €
PTA50-10-125/SS	50	M10	125	29	14	19	154	4000	✓	18,14 €
PTA50-12-75/SS	50	M12	75	29	14	19	104	4000	✓	15,95 €
PTA50-12-125/SS	50	M12	125	29	14	19	154	4000	✓	18,14 €
PTA50-16-75/SS	50	M16	75	34	13	19	109	4000	✓	18,62 €
PTA50-16-100/SS	50	M16	100	34	13	19	134	4000	-	19,34 €
PTA50-16-150/SS	50	M16	150	34	13	19	184	4000	-	21,27 €

*Depending on availability - Dimensions in mm

Our other products



CHNrb

Warning chain with red and white links, Steel



DIV_SS

Stainless steel locking bolt, With grip - Stainless steel



HLC19

Right angle spiro bevel gearbox, Up to 43Nm




CMA

Eye bolt, Steel



PRF4545

Standard aluminium profile, 45 x 45 mm

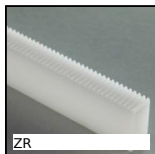

ZR

Plastic rack, Delrin



CNA-CNG

Right angled mounting plate, Right angled mounting plate for clevis



PO

Pull handle - Multi-sector, Smooth hole




CHT

Asynchronous AC Motor, 0.18 to 0.55kW



PR40

Articulated foot Ø50, Ø 50

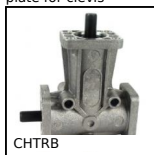

CHTRB

Single and dual output gearboxes, Up to 53,1 Nm



CHM63

Worm and wheel gear reducer, up to 196 Nm

Complementary products