

Articulated foot with sheet metal base Ø50

Max load: 4000N
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Food industry

Sole in EPDM, blue




Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

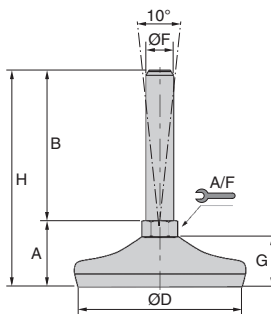

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA50-10-75/SS/EB	50	M10	75	29	14	19	104	4,000	17,56€
PTA50-10-125/SS/EB	50	M10	125	29	14	19	154	4,000	19,83€
PTA50-12-75/SS/EB	50	M12	75	29	14	19	104	4,000	17,56€
PTA50-12-125/SS/EB	50	M12	125	29	14	19	154	4,000	19,83€
PTA50-16-75/SS/EB	50	M16	75	34	13	19	109	4,000	20,38€
PTA50-16-100/SS/EB	50	M16	100	34	13	19	134	4,000	21,14€
PTA50-16-150/SS/EB	50	M16	150	34	13	19	184	4,000	23,13€

* Depending on availability - Dimensions in mm

Our other products



CLSCLP_SS
Clevis components,
short version,
Stainless steel - short
range



PRF-SMA
Closing system for
aluminium profile,
Easily adjustable lock



H3
Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



RURp
Swivel castor with
double brake,
Polyurethane -
Aluminium rim (Free



CHAR6035
Spring hinge,
screwed/welded



INO
Internal gear, Steel
20NC2



PSG055
Spur gear - precision
range, Stainless steel
316



RBN
Wheel, Rubber tyre -
Polypropylene rim



PM4
Worm and wheel set,
Bronze



UCP_SS
Stainless steel pillow
block bearing,



SBS_L
Chain link, Stainless
steel



GE
Toggle latches,
Miniature

Complementary products



PTA80ssEB
Articulated foot with
sheet metal base
Ø80, Articulated foot



PTA100ssEB
Articulated foot with
sheet metal base
Ø100, Articulated foot



PAMF80EB
Articulated foot with
sheet metal base
Ø80, Articulated foot



PAMF100EB
Articulated foot with
sheet metal base
Ø100, Articulated foot