

Articulated foot with sheet metal base Ø50

Max load: 4000N
Rubber sole in EPDM, blue


- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

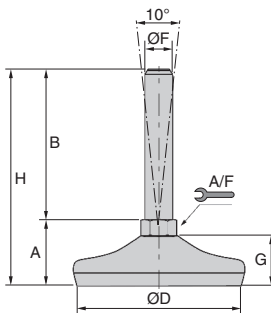

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA50-10-75/SS/EB	50	M10	75	29	14	19	104	4,000	17,56€
PTA50-10-125/SS/EB	50	M10	125	29	14	19	154	4,000	19,83€
PTA50-12-75/SS/EB	50	M12	75	29	14	19	104	4,000	17,56€
PTA50-12-125/SS/EB	50	M12	125	29	14	19	154	4,000	19,83€
PTA50-16-75/SS/EB	50	M16	75	34	13	19	109	4,000	20,38€
PTA50-16-100/SS/EB	50	M16	100	34	13	19	134	4,000	21,14€
PTA50-16-150/SS/EB	50	M16	150	34	13	19	184	4,000	23,13€


* Depending on availability - Dimensions in mm

Our other products




SH1

 Parallel axis helical gear, Machined plastic (delrin)



AC

 Strike for toggle latch, 20mm



T5_11

T type timing pulley, T5 aluminium



BKGS

Backlash free coupling Gerwah®, from 1.2 to 450Nm



SVT20

Screwjack with travelling screw, with translating screw



MPE

Hexagonal spacer, Steel



SA_SAKH

Housing for linear bearing, Closed - light load



PRES4HR

Manual workbench press, Force up to 600kg



PRF_ART

Articulated bracket for use with aluminium profile, With clamping



PCLA_M

Technopolymer clamping lever - female, Plastic



PTA100

Articulated levelling foot, pressed base Ø100, Ø 100



BOXsap

Boxed set of spring pins ISO8752, Boxed set - Split ISO 8752

Complementary products



PTA80ssEB

Articulated foot with sheet metal base Ø80, Articulated foot



PTA100ssEB

Articulated foot with sheet metal base Ø100, Articulated foot



PAMF80EB

Articulated foot with sheet metal base Ø80, Articulated foot



PAMF100EB

Articulated foot with sheet metal base Ø100, Articulated foot