

Articulated foot with sheet metal base Ø50

Max load: 4000N
Rubber sole in EPDM, blue


- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

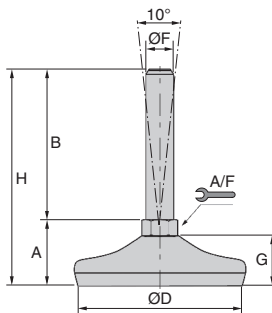

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA50-10-75/SS/EB	50	M10	75	29	14	19	104	4,000	17,56€
PTA50-10-125/SS/EB	50	M10	125	29	14	19	154	4,000	19,83€
PTA50-12-75/SS/EB	50	M12	75	29	14	19	104	4,000	17,56€
PTA50-12-125/SS/EB	50	M12	125	29	14	19	154	4,000	19,83€
PTA50-16-75/SS/EB	50	M16	75	34	13	19	109	4,000	20,38€
PTA50-16-100/SS/EB	50	M16	100	34	13	19	134	4,000	21,14€
PTA50-16-150/SS/EB	50	M16	150	34	13	19	184	4,000	23,13€

* Depending on availability - Dimensions in mm

Our other products



M0

Worm and wheel set,
Bronze



G0

Steel spur gear, Steel
20NCD2



PTGT

Tensioner pulley, For
V belts



UTKpwrr

V shaped channel
UtiliTrak®, V rail




PSG3S

Spur gear - precision
range, Stainless steel
303



BABam

 Self-locking ball pin
lifting ring for
threaded hole, Self-
locking




M0

Worm and wheel set,
Machined plastic
(delrin)



MBF

 Threaded blocking
clamp, Threaded
locking clamp



B

Steel bevel gear, 1:1



RBNpl

Swivel castor with
double brake, Steel -



PCS37K

Chain sprocket with
hardened teeth,



SH0

Parallel axis helical
gear, Steel 20NCD2

Complementary products



PTA80ssEB

Articulated foot with
sheet metal base
Ø80, Articulated foot



PTA100ssEB

Articulated foot with
sheet metal base
Ø100, Articulated foot



PAMF80EB

Articulated foot with
sheet metal base
Ø80, Articulated foot



PAMF100EB

Articulated foot with
sheet metal base
Ø100, Articulated foot