

Articulated foot with sheet metal base Ø50

Max load: 4000N
Rubber sole in EPDM, blue


- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

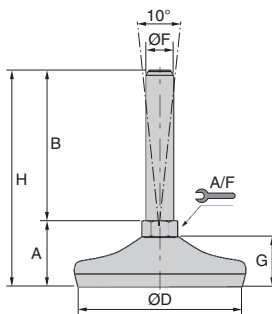

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA50-10-75/SS/EB	50	M10	75	29	14	19	104	4,000	17,56€
PTA50-10-125/SS/EB	50	M10	125	29	14	19	154	4,000	19,83€
PTA50-12-75/SS/EB	50	M12	75	29	14	19	104	4,000	17,56€
PTA50-12-125/SS/EB	50	M12	125	29	14	19	154	4,000	19,83€
PTA50-16-75/SS/EB	50	M16	75	34	13	19	109	4,000	20,38€
PTA50-16-100/SS/EB	50	M16	100	34	13	19	134	4,000	21,14€
PTA50-16-150/SS/EB	50	M16	150	34	13	19	184	4,000	23,13€

* Depending on availability - Dimensions in mm

Our other products



BLHT50
Right angled gearbox, from 11.50 to 30 Nm



PMC150_M16
Anti-vibration machine mount, Square base plate



SH3
Parallel axis helical gear, Machined plastic (delrin)



PV1R
Adjustable suction-cup support, Standard grip



P60
Worm and wheel gear reducer, up to 118 Nm



HTD5M_15
HTD Heavy duty timing pulley, HTD5 Steel



 
BVR
Adjustable screw stop, Steel



UTKswc
Utiltrak® 3 wheels carriage, Series V precision steel wheel



LC
Friction clutch, 190 to 1800 Nm



PB
Plastic deep groove ball bearing, Plastic - balls material : stainless...



BFM2
Flanged bronze nut, Bronze - 2 threads



MFBS
Stainless steel flexible bellows coupling, Stainless steel - with se...

Complementary products



PTA80ssEB
Articulated foot with sheet metal base Ø80, Articulated foot



PTA100ssEB
Articulated foot with sheet metal base Ø100, Articulated foot



PAMF80EB
Articulated foot with sheet metal base Ø80, Articulated foot



PAMF100EB
Articulated foot with sheet metal base Ø100, Articulated foot