

Articulated foot with sheet metal base Ø50

Max load: 4000N
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Food industry

Sole in EPDM, blue




Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

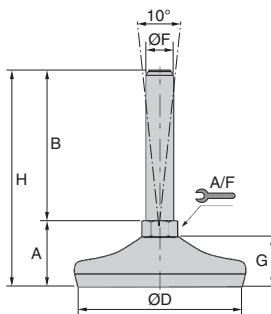

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA50-10-75/SS/EB	50	M10	75	29	14	19	104	4,000	17,56€
PTA50-10-125/SS/EB	50	M10	125	29	14	19	154	4,000	19,83€
PTA50-12-75/SS/EB	50	M12	75	29	14	19	104	4,000	17,56€
PTA50-12-125/SS/EB	50	M12	125	29	14	19	154	4,000	19,83€
PTA50-16-75/SS/EB	50	M16	75	34	13	19	109	4,000	20,38€
PTA50-16-100/SS/EB	50	M16	100	34	13	19	134	4,000	21,14€
PTA50-16-150/SS/EB	50	M16	150	34	13	19	184	4,000	23,13€

* Depending on availability - Dimensions in mm

 
Our other products



Spur gear - precision range, Pre-hardened Steel 35NCD6

Clamp lever with threaded insert, Plastic

Wheel fixed with plate, Steel - Polyamide



RPP-heavy duty timing belt, RPP8



Heavy duty timing pulley, HTD8 Steel



Wheel, Swivel with brake



Adjustable gas spring, Steel



Digital position indicator, 5 numbers



Thermoplastic T handle, With threaded spindle



Tools Hygienic Usit® and Hygienic Design®,



Right angle bevel gearbox, Up to 182Nm

Complementary products



Articulated foot with sheet metal base, Articulated foot



Articulated foot with sheet metal base, Articulated foot



Articulated foot with sheet metal base, Articulated foot



Articulated foot with sheet metal base, Articulated foot