

Ste Sta Articulated levelling foot, pressed base Ø80

Accepts loads up to 10.000N

PTA80
PTA80ss

- Articulated foot
- Up to +/- 10° from vertical
- Materials:


Steel version:

Base: Galvanised sheet steel C40
Shaft: Galvanised steel (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:


Base: Stainless steel sheet
304
Shaft: Stainless steel 304
(nut not supplied)
Sole: Vulcanised NBR
rubber, hardness 80° Shore

Stainless
steel version,
sanded finish

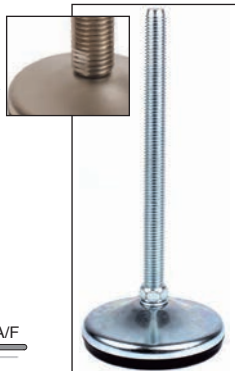

Advantages

- Excellent Price-Quality ratio

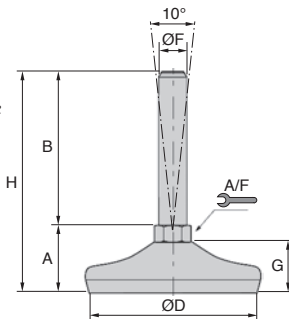

DISCOUNTS

Qty	1+	15+	20+	25+	40+
Disc. List	-	-5%	-10%	-15%	On request

Part number	ØD	Thread ØF	B	A	A/F	G	H	Load static (N)	Stock*	Price each 1 to 14
Steel foot										
PTA80-12-100	80	M12	100	35	14	25	135	10000	✓	20,92 €
PTA80-12-150	80	M12	150	35	14	25	185	10000	-	23,24 €
PTA80-16-100	80	M16	100	35	16	25	135	10000	✓	23,08 €
PTA80-16-150	80	M16	150	35	16	25	185	10000	-	25,53 €
PTA80-20-100	80	M20	100	36	20	25	136	10000	-	24,24 €
PTA80-20-150	80	M20	150	36	20	25	186	10000	-	27,21 €
PTA80-20-200	80	M20	200	36	20	25	236	10000	✓	29,72 €
Stainless steel foot										
PTA80-12-100/SS	80	M12	100	35	14	25	135	10000	✓	31,90 €
PTA80-12-150/SS	80	M12	150	35	14	25	185	10000	-	34,27 €
PTA80-16-100/SS	80	M16	100	35	13	25	135	10000	-	34,27 €
PTA80-16-150/SS	80	M16	150	35	13	25	185	10000	✓	36,64 €
PTA80-20-100/SS	80	M20	100	38	17	25	138	10000	-	38,44 €
PTA80-20-150/SS	80	M20	150	38	17	25	188	10000	✓	41,36 €
PTA80-20-200/SS	80	M20	200	38	17	25	238	10000	✓	45,83 €

*Depending on availability - Dimensions in mm

Our other products



CHAsb63
Hinge without pin,
Polymer pin hinge



EMAS
Antistatic knurled nut,
Antistatic




CLSCLP
Clevis components,
short version, Steel -
Short range



SCA_SS
Stainless steel flat
cable clamp, Stainless
steel



AT10-25ECO
AT type timing pulley,
Economy range -
AT10 aluminium

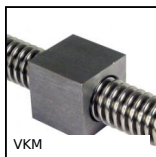


VKM
Square steel nut,
Steel - 1 thread




MRA_SS
Stainless steel Quick
link, Stainless steel



BABA
Ball pin lifting ring,
Steel

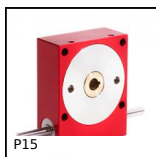

P15
Worm and wheel gear
reducer, up to 3,75
Nm

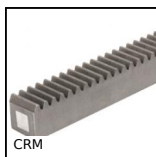

CRM
Moulded nylon rack,
Nylon



BLHB50
Right angled gearbox,
bored shafts, up to 30
Nm



WING
Manually tightened
wing nut, Stainless
steel DIN 314/315

Complementary products



PR85
Articulated foot Ø83,
Ø 83