

SteSta Articulated levelling foot, pressed base Ø80

Accepts loads up to 10.000N

PTA80
PTA80ss

- Articulated foot
- Up to +/- 10° from vertical
- Materials:



Steel version:

Base: Galvanised sheet steel C40
Shaft: Galvanised steel (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:

Base: Stainless steel sheet
304
Shaft: Stainless steel 304
(nut not supplied)
Sole: Vulcanised NBR
rubber, hardness 80° Shore

Stainless
steel version,
sanded finish

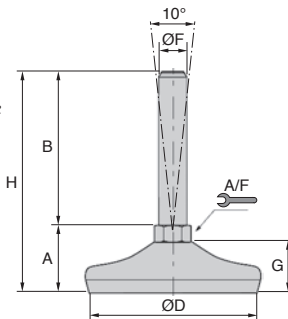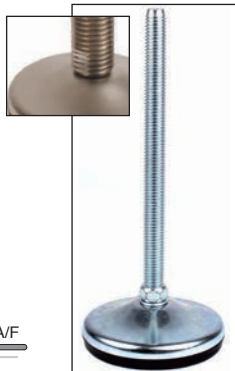

Advantages

- Excellent Price-Quality ratio

DISCOUNTS

Qty	1+	15+	20+	25+	40+
Disc. List	-5%	-10%	-15%	On request	On request

Part number	ØD	Thread ØF	B	A	A/F	G	H	Load static (N)	Stock*	Price each 1 to 14
Steel foot										
PTA80-12-100	80	M12	100	35	14	25	135	10000	✓	20,92 €
PTA80-12-150	80	M12	150	35	14	25	185	10000	-	23,24 €
PTA80-16-100	80	M16	100	35	16	25	135	10000	✓	23,08 €
PTA80-16-150	80	M16	150	35	16	25	185	10000	-	25,53 €
PTA80-20-100	80	M20	100	36	20	25	136	10000	-	24,24 €
PTA80-20-150	80	M20	150	36	20	25	186	10000	-	27,21 €
PTA80-20-200	80	M20	200	36	20	25	236	10000	✓	29,72 €
Stainless steel foot										
PTA80-12-100/SS	80	M12	100	35	14	25	135	10000	✓	31,90 €
PTA80-12-150/SS	80	M12	150	35	14	25	185	10000	-	34,27 €
PTA80-16-100/SS	80	M16	100	35	13	25	135	10000	-	34,27 €
PTA80-16-150/SS	80	M16	150	35	13	25	185	10000	✓	36,64 €
PTA80-20-100/SS	80	M20	100	38	17	25	138	10000	-	38,44 €
PTA80-20-150/SS	80	M20	150	38	17	25	188	10000	✓	41,36 €
PTA80-20-200/SS	80	M20	200	38	17	25	238	10000	✓	45,83 €

*Depending on availability - Dimensions in mm

Our other products



ACLERP

Roller block for aluminium profile, Without guide rail



DOMI30

Accessories, Fixing kit



PLA

Flat magnet, Flat magnet



MLY

Bow shackle with eye bolt, Steel



DEP

Tools Hygienic Usit® and Hygienic Design®, Protective insert for s...



PM4

Worm and wheel set, Machined plastic (delrin)



PV2R

Adjustable suction-cup support, Increased grip



LVT

Miniature motorised actuator 2A, 2 amperes



GAL_25

Ø25 conveyor roller, Without ball bearing



NIN

Self-locking nut, Steel



G2

Steel spur gear, Steel 20NCD2



UCFL_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel

Complementary products



PTKss

Foot for the food industry, Stainless steel - 3-A standard



PTKFss

Fixable foot for the food industry, Stainless steel - 3-A standard