

# Ste Sta Articulated levelling foot, pressed base Ø80

Accepts loads up to 10.000N

PTA80  
PTA80ss

- Articulated foot
- Up to +/- 10° from vertical
- Materials:



### Steel version:

Base: Galvanised sheet steel C40  
Shaft: Galvanised steel (nut not supplied)  
Sole: Vulcanised NBR rubber, hardness 80° Shore

### Stainless steel version:

Base: Stainless steel sheet  
304  
Shaft: Stainless steel 304  
(nut not supplied)  
Sole: Vulcanised NBR  
rubber, hardness 80° Shore

Stainless  
steel version,  
sanded finish

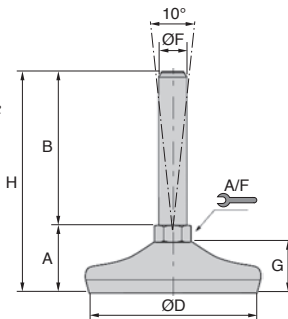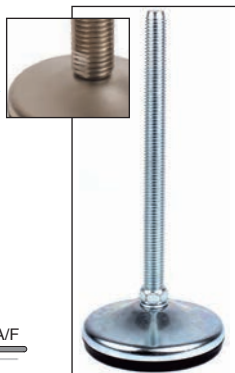

## Advantages

- Excellent Price-Quality ratio

## DISCOUNTS

Qty	1+	15+	20+	25+	40+
Disc. List	-	-5%	-10%	-15%	On request

Part number	ØD	Thread ØF	B	A	A/F	G	H	Load static (N)	Stock*	Price each 1 to 14
<b>Steel foot</b>										
PTA80-12-100	80	M12	100	35	14	25	135	10000	✓	20,92 €
PTA80-12-150	80	M12	150	35	14	25	185	10000	-	23,24 €
PTA80-16-100	80	M16	100	35	16	25	135	10000	✓	23,08 €
PTA80-16-150	80	M16	150	35	16	25	185	10000	-	25,53 €
PTA80-20-100	80	M20	100	36	20	25	136	10000	-	24,24 €
PTA80-20-150	80	M20	150	36	20	25	186	10000	-	27,21 €
PTA80-20-200	80	M20	200	36	20	25	236	10000	✓	29,72 €
<b>Stainless steel foot</b>										
PTA80-12-100/SS	80	M12	100	35	14	25	135	10000	✓	31,90 €
PTA80-12-150/SS	80	M12	150	35	14	25	185	10000	-	34,27 €
PTA80-16-100/SS	80	M16	100	35	13	25	135	10000	-	34,27 €
PTA80-16-150/SS	80	M16	150	35	13	25	185	10000	✓	36,64 €
PTA80-20-100/SS	80	M20	100	38	17	25	138	10000	-	38,44 €
PTA80-20-150/SS	80	M20	150	38	17	25	188	10000	✓	41,36 €
PTA80-20-200/SS	80	M20	200	38	17	25	238	10000	✓	45,83 €

\*Depending on availability - Dimensions in mm

## Our other products



SMS  
Spiral bevel gear, 1:1



CHAR5050\_Z  
Spring hinge, screwed



CHA138  
Screwed hinge with threaded insert, 138 degrees



PSG125HC  
Skive hobbed spur gears - precision range, Case hardened steel 20NCD2



SVG  
Adjustable latch clamp with strike plate, Stroke from 118mm to 130,5mm



BOX-WM  
Box set of washer - DIN125, Box set of steel washers



VTLF  
3 lobed handle, Polyamide - Brass



PLM-20SC  
Cylindrical magnet, Cylindrical magnet




ZBconique  
Machined plastic bevel gear, 1:1



HRV  
V-rail guidance Simple Select®



 GAL21  
Conveyor wheel, Plastic



TBV  
Manual lifting tables, 20kg

## Complementary products



PR85  
Articulated foot Ø83, Ø 83