

SteSta Articulated levelling foot, pressed base Ø80

Accepts loads up to 10.000N

PTA80
PTA80ss

- Articulated foot
- Up to +/- 10° from vertical
- Materials:



Steel version:

Base: Galvanised sheet steel C40
Shaft: Galvanised steel (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:

Base: Stainless steel sheet
304
Shaft: Stainless steel 304
(nut not supplied)
Sole: Vulcanised NBR
rubber, hardness 80° Shore

Stainless
steel version,
sanded finish

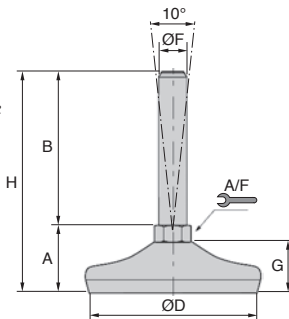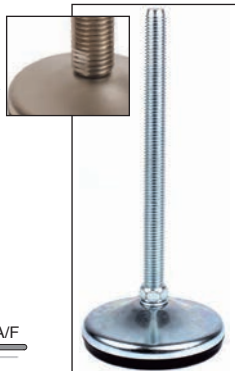

Advantages

- Excellent Price-Quality ratio

DISCOUNTS

Qty	1+	15+	20+	25+	40+
Disc. List	-	-5%	-10%	-15%	On request

Part number	ØD	Thread ØF	B	A	A/F	G	H	Load static (N)	Stock*	Price each 1 to 14
Steel foot										
PTA80-12-100	80	M12	100	35	14	25	135	10000	✓	20,92 €
PTA80-12-150	80	M12	150	35	14	25	185	10000	-	23,24 €
PTA80-16-100	80	M16	100	35	16	25	135	10000	✓	23,08 €
PTA80-16-150	80	M16	150	35	16	25	185	10000	-	25,53 €
PTA80-20-100	80	M20	100	36	20	25	136	10000	-	24,24 €
PTA80-20-150	80	M20	150	36	20	25	186	10000	-	27,21 €
PTA80-20-200	80	M20	200	36	20	25	236	10000	✓	29,72 €
Stainless steel foot										
PTA80-12-100/SS	80	M12	100	35	14	25	135	10000	✓	31,90 €
PTA80-12-150/SS	80	M12	150	35	14	25	185	10000	-	34,27 €
PTA80-16-100/SS	80	M16	100	35	13	25	135	10000	-	34,27 €
PTA80-16-150/SS	80	M16	150	35	13	25	185	10000	✓	36,64 €
PTA80-20-100/SS	80	M20	100	38	17	25	138	10000	-	38,44 €
PTA80-20-150/SS	80	M20	150	38	17	25	188	10000	✓	41,36 €
PTA80-20-200/SS	80	M20	200	38	17	25	238	10000	✓	45,83 €

*Depending on availability - Dimensions in mm

Our other products



PW_PWG2

Worm - precision range, Stainless steel



MEF

Cylindrical sintered ferrous bush, Self-lubricating FP20 ferrous all...



RPC

Wheel, Polyamide




SCA_SS

Stainless steel flat cable clamp, Stainless steel



BLHM30

 Right angled gearbox, double output shafts, up to 4.4 Nm



T2

T type timing belt, T2.5 Steel cored polyurethane



BPHRF

Ball transfer unit housed spring loaded, High



RHTplss

High Temperature Castor, up to 200kg



MAC

Carabiner DIN5299 steel, Steel



HRV

V-rail guidance Simple Select®



EHD08-3

Internal epicyclic servo reducers, from



BLHT70

Right angled gearbox, from 26 to 128 Nm

Complementary products



PTKss

Foot for the food industry, Stainless steel - 3-A standard



PTKFss

Fixable foot for the food industry, Stainless steel - 3-A standard