

SteSta Articulated levelling foot, pressed base Ø80

Accepts loads up to 10.000N

PTA80
PTA80ss

- Articulated foot
- Up to +/- 10° from vertical
- Materials:



Steel version:

Base: Galvanised sheet steel C40
Shaft: Galvanised steel (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:

Base: Stainless steel sheet
304
Shaft: Stainless steel 304
(nut not supplied)
Sole: Vulcanised NBR
rubber, hardness 80° Shore

Stainless
steel version,
sanded finish

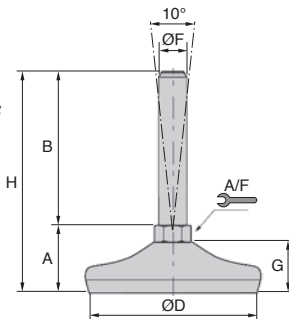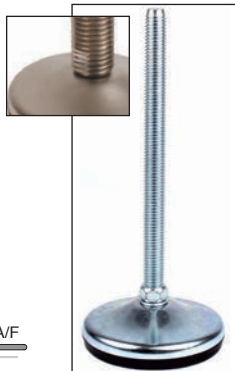

Advantages

- Excellent Price-Quality ratio


DISCOUNTS

Qty	1+	15+	20+	25+	40+
Disc. List	-5%	-10%	-15%	On request	

Part number	ØD	Thread ØF	B	A	A/F	G	H	Load static (N)	Stock*	Price each 1 to 14
Steel foot										
PTA80-12-100	80	M12	100	35	14	25	135	10000	✓	20,92 €
PTA80-12-150	80	M12	150	35	14	25	185	10000	-	23,24 €
PTA80-16-100	80	M16	100	35	16	25	135	10000	✓	23,08 €
PTA80-16-150	80	M16	150	35	16	25	185	10000	-	25,53 €
PTA80-20-100	80	M20	100	36	20	25	136	10000	-	24,24 €
PTA80-20-150	80	M20	150	36	20	25	186	10000	-	27,21 €
PTA80-20-200	80	M20	200	36	20	25	236	10000	✓	29,72 €
Stainless steel foot										
PTA80-12-100/SS	80	M12	100	35	14	25	135	10000	✓	31,90 €
PTA80-12-150/SS	80	M12	150	35	14	25	185	10000	-	34,27 €
PTA80-16-100/SS	80	M16	100	35	13	25	135	10000	-	34,27 €
PTA80-16-150/SS	80	M16	150	35	13	25	185	10000	✓	36,64 €
PTA80-20-100/SS	80	M20	100	38	17	25	138	10000	-	38,44 €
PTA80-20-150/SS	80	M20	150	38	17	25	188	10000	✓	41,36 €
PTA80-20-200/SS	80	M20	200	38	17	25	238	10000	✓	45,83 €

*Depending on availability - Dimensions in mm

 Our other products



PRZ

Wear strip for slat top chain, Z profile to be filled




GLT3E-58

Telescopic drawer,



MSP19

 Masterplate® glueable insert Ø19/Ø20, Cylindrical with nut



M2

Worm and wheel set, Machined plastic (delrin)



F7-SN

Multifunction display, Articulated support



LACM_SS

Stainless steel cam lever, Female




VRSSss

Male swivelling lifting rings stainless steel, Male swivelling - s...



EMR

Fast-locking knurled nut, Knurled

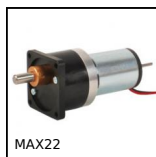

MAX22

Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



VTA

Vari-Tork® slip friction clutch, 0.53 to 1.32 Nm



E30

Right angle helical reducers, from 1.50 to 9 Nm



SLV

Vertical toggle clamp, Vertical Lever Clamp - stainless steel

Complementary products



PTKss

Foot for the food industry, Stainless steel - 3-A standard



PTKFss

Fixable foot for the food industry, Stainless steel - 3-A standard